

2.4GHz & Sub carrier 5.5MHz Series:

Model	MST-AB200M	MST-AB100M	TXT-AB2	MST-AB020M	MST-AB005M	MST-AB010M	MST-AB060M	MST-AB6
RF Output Power	2W	1W	200mW	200mW	50mW	100mW	600mW	600mW
Operating voltage	DC12V	DC12V	DC 9V	DC 5V	DC 12V	DC 12V	DC 5.5V	DC 9V
Operating current	850mA	450mA	900mA	200mA	120mA	140mA	330mA	900mA
Dimensions(mm)	61 x 64 x 35	48 x 61 x 35	48 x 61 x 35	48 x 61 x 35	48 x 61 x 35	48 x 61 x 35	48 x 61 x 35	48 x 61 x 35
Weight(g)	170	129	138	25	36	26	32	138
Video input	1Vp-p							
Audio input	2Vp-p(max)							
Audio sub carrier	5.5MHz							
Operating temperature	-10~40 Degrees C							
Operating humidity	20~80%							
Channel Frequency(PLL)	2413,2432,2451,2470MHz							
Frequency Deviation	200kHz							

1.2GHz & Sub carrier 5.5MHz Series:

Model	TXT-BB5	TXT-BB1	MST-BB200M	MST-BB010M	MST-BB050M	MST-BB005M
RF Output Power	500mW	100mW	200mW	100mW	500mW	50mW
Operating voltage	DC 9V	DC 9V	DC 12V	DC 12V	DC 12V	DC 5V
Operating current	900mA	900mA	850mA	140mA	280mA	80mA
Dimensions(mm)	55 x 86 x 20	55 x 70 x 15	61 x 64 x 35	24 x 29 x 8.5	49 x 25 x 8	16 x 16 x 4
Weight(g)	138	84	170	25	32	14.5
Video input	1Vp-p					
Audio input	2Vp-p(max)					
Audio sub carrier	5.5MHz					
Operating temperature	-10~40 Degrees C					
Operating humidity	20~80%					
Channel Frequency(PLL)	1080, 1120, 1160, 1200MHz					
Frequency Deviation	200kHz					

0.9GHz & Sub carrier 5.5MHz Series:

Model	MST-CB050M
Channel Frequency(PLL)	910, 980, 1010, 1040MHz
Frequency Deviation	200kHz
RF Output Power	500mW
Video input	1Vp-p
Audio input	2Vp-p(max)
Audio sub carrier	5.5MHz
Operating voltage	DC 12V
Operating current	140mA
Operating temperature	-10~40 Degrees C
Operating humidity	20~80%
Dimensions(mm)	26 x 50 x 8
Weight(g)	20

0.9GHz~2.4GHz(Non PLL):


Model	MST-A1NP	MST-B1NP	MST-C1NP
Channel Frequency(PLL)	910, 980, 1010, 1040MHz		
Frequency Deviation	200kHz		
RF Output Power	1mW		
Video input	1Vp-p		
Audio input	2Vp-p(max)		
Audio sub carrier	N/A		
Operating voltage	DC 5V		
Operating current	30mA		
Operating temperature	-10~40 Degrees C		
Operating humidity	20~80%		
Dimensions(mm)	8 x 11		
Weight(g)	12		

Instruction drawing(example for wireless)


Transmitter:TXT-AB2

Model	DC Plug	Module
MST-XXXXM		■
MST-XXXXM-P	■	■

Receiver:MSR-BB400M

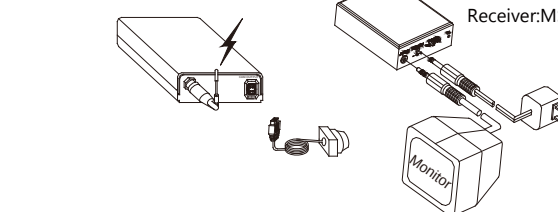

MST-AB200M MST-BB200M	MST-AB100M MST-BB100M	TXT-AB2, TXT-AB6 TXT-BB1, TXT-BB2	MST-AB010M	MST-AB020M MST-BB010M
				
MST-AB005M	MST-AB060M MST-BB005M, MST-CB050M	MST-(A, B, C)1NP	MST-AB020M MST-BB010M	MST-AB010M MST-BB005M
				

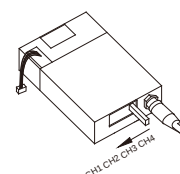

Specification


Model	MSR-A2410B	MSR-B1210B	MSR-C0910B
Channel Frequency(PLL)	2413, 2432 2451, 2470	1080, 1120 1160, 1200	910, 980 1010, 1040
Frequency Deviation	200kHz		
Video input	1Vp-p 75 ohm		
Audio input	2Vp-p 10k ohm		
Audio sub carrier	5.5MHz		
Operating voltage	DC 12V		
Operating current	350mA		
Operating temperature	-10~40 Degrees C		
Operating humidity	20~80%		
Dimensions(mm)	114 x 80 x 20		
Weight(g)	165		

Model	MRX-2400B	MRX-1200B	MRX-0900B
Channel Frequency(PLL)	2413, 2432 2451, 2470	1080, 1120 1160, 1200	910, 980 1010, 1040
Video input	1Vp-p Composite video		
Audio input	2Vp-p (max)		
Audio sub carrier	5.5MHz		
Operating voltage	DC 5V		
Power current	360mA		
Battery charge time	2.5Hrs		
Operating temperature	-10~40 Degrees C		
Operating humidity	20~80%		
Dimensions(mm)	110 x 67 x 21.5		
Weight(g)	117		

Dimension:


MSR-A2410B, MSR-B1210B, MSR-C0910B

- 2.4GHz Wireless receiver + auto-switcher + metal housing.
- Receivers can be adjusted to mute mode or changed intervals of scanning.
- Receivers will automatically receive new signals from any one of newly added cameras. Producing clear audio affect and stable video effect.
- Being able to hooked up to 4 cameras and sending signals simultaneously.

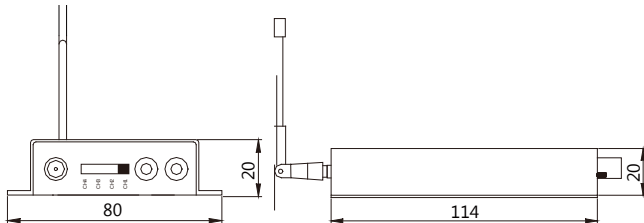

MRX-2400B, MRX-1200B, MRX-0900B

- Receivers will automatically receive new signals from any one of newly added cameras. Producing clear audio affect and stable video effect.
- Receivers can be adjusted to mute mode or changed intervals of scanning.
- POWER: Li-Ion Rechargeable Battery or DC 5V Using compatible Nokia cell phone battery BL-5C
- 2.4GHz Wireless receiver + auto-switcher + metal housing.
- 4CH & Auto Switcher
- Low Power & channel LED Display

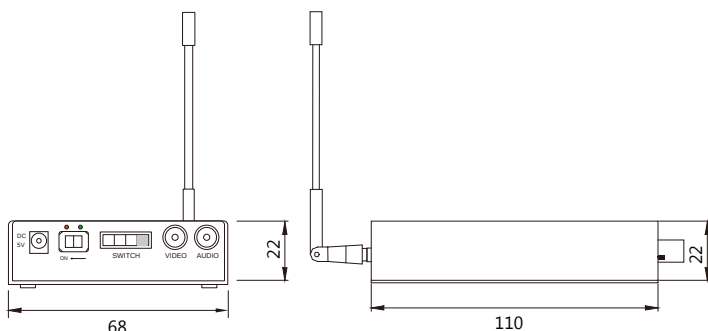

Receiver

MSR-A2410B, MSR-B1210B, MSR-C0910B



MRX-2400B, MRX-1200B, MRX-0900B



Instruction Drawing (Example for wireless):

