


Specification

Mobile Digital Video Recorder	
Storage media type	SD / MMC Card slot (support up to 2GB) , Built-in flash memory 128 MB
LCD display	2.5" LTPS TFT LCD 960 x 240 , 230K pixels / 262K Color
Interface	2 in 1 MiniUSB (USB2.0 / Power in) ; 4 in 1 earphone jack (Video out / earphone jack / external microphone / AV in)
Video out / Video in	TV OUT (NTSC / PAL) / AV IN (NTSC / PAL)
Extend interface	Extend DC power 9V out for camera and AV in
AV recorder resolution	640 x 480 (VGA) / max 30 fps
AV audio quality	2 modes : radio quality (16KHz) / CD quality (48KHz)
AV recorder quality	MPEG4 : best fine normal basic economy
Voice recorder	2 modes: radio quality (16KHz)/CD quality (48KHz)
Format support	JPEG ASF WAV MP3 WMA
Language support	12 languages: English, German, French, Spanish, Italian, Portuguese , Japanese, simple Chinese, tradition Chinese, Korean, Polish, Turkey
Battery	Rechargeable LI-ION battery 3.7 V /920mA , compatible with NP60 type battery
Adapter	5V DC adapter (USB port) / USB cable
Weight(g)	95g (with battery)
Size	18 x 68 x 81 (L x W x H) mm
Extend Interface	Extend DC Power 9V out for Camera and AV in Scheduled recording function (12 event) Special Power save button (monitor sleep mode)



MP-415E

Dimension

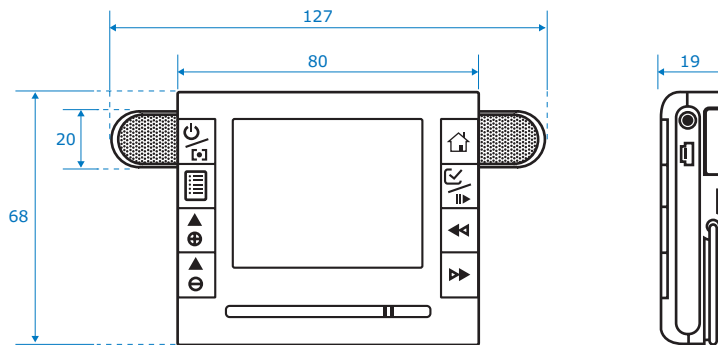

unit : mm

Other model



SS-L1475

CCD snake camera with white LED light



MO-L806

CMOS snake camera with white LED light