

Specification

Snake CCD Camera


CCD SNAKE CAMERA WITH LED LIGHT

Model	SS-L1475	SS-6875
Video system	NTSC / PAL	EIA / CCIR
Number of effective pixels	NTSC(EIA)	510 x 492
	PAL(CCIR)	500 x 528
Image sensor	1/4" CCD Camera	
Resolution(TV Lines)	350	570
S/N Ratio	more than 48dB	
AGC control	more than +27dB	
Minimum illumination	0.2 LUX / F1.4	0.02 LUX / F1.2
Electronic shutter	1/50 - 1/100,000	
Horizontal sync frequency	NTSC(EIA)-15.734kHz / PAL(CCIR)-15.625kHz	
Vertical sync frequency	NTSC(EIA)-60Hz / PAL(CCIR)-50Hz	
Camera consumption	0.45	
Video output	1Vp-p , 75ohm composite	
Audio output	Frequency 20-16,000Hz , S/N ratio more than 58 SPL(at 1000Hz)(Ordering in advance)	
Built-in lens	4.0 mm / F2.0	
Lens angle	4.0 mm / 70 Degree	
Power source	DC 12V(Standard)	
Power current	150 mA	
Dimension (mm)	Ø16 x 23.5 (mm)	Ø16 x 29 (mm)



SS-1475

Dimensions

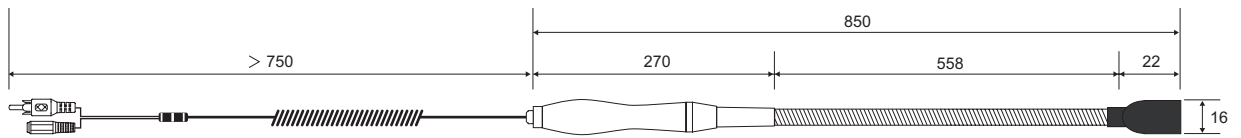

Unit: mm (Approx)

Usage Example



- Ⓐ Snake camera with LED light.
- Ⓑ Micro Video Monitor

Feature

1/4" CCD CAMERA

SONY COLOR CCD Image Sensor

75cm flexible cable (flexible iron pipe protect) .

4.0mm/F2.0 Built-In Lens (Default focus 15cm)

Other Model



MO-L806

CMOS Snake camera with LED light

Specification

CMOS SNAKE CAMERA					
Model	MO-L806	MO-L575	MO-S575	MO-L1675	MO-S1675
Video system	NTSC / PAL		NTSC Only	NTSC / PAL	
Number of effective pixels	NTSC(EIA)	306 x 240		510 x 492	
	PAL(CCIR)	366 x 288		628 x 582	
Image sensor	1/5"PAL / 1/6"NTSC		1/4" Color	1/3" Color	
Resolution(TV Lines)	240		380		
S/N Ratio	more than 48dB				
AGC control	more than +27dB				
Minimum illumination	2 LUX		1.5 LUX	1 LUX	
Electronic shutter	1/50 - 1/57,000		1/50 - 1/63,000	1/50 - 1/125,000	
Horizontal sync frequency	NTSC(EIA)-15.734kHz / PAL(CCIR)-15.625kHz				
Vertical sync frequency	NTSC(EIA)-60Hz / PAL(CCIR)-50Hz				
Camera consumption	0.45				
Video output	1Vp-p , 75ohm composite				
Audio output	Frequency 20-16,000Hz , S/N ratio more than 58 SPL(at 1000Hz)(Ordering in advance)				
Built-in lens	2.8 mm / F2.0		4.0 mm / F2.0		
Lens angle	2.8 mm / 60 Degree		4.0 mm / 64 Degree	4.0 mm / 80 Degree	
Power source	DC 9 -12V(Standard)				
Power current	35 mA			100 mA	
Dimension (mm)	9.2 x 14 (mm)	12 x 25 (mm)	12 x 23 (mm)	15 x 41.5 (mm)	

Snake Cmos Camera

MO-L806	MO-L575	MO-S575	MO-L1675 , MO-S1675
<p>(With LED Light)</p>	<p>(With LED Light)</p>		<p>(With LED Light - MO-L1675)</p>

75 ~ 3000 cm (order in advance)



Feature

Snake camera with LED light
75cm flexible cable (flexible iron pipe protect)
Waterproof (IP-67)