


MO-S3514G



Feature

- 2.5mm headphone plug out
- Hidden spy camera in Earphone
- 1/3" CMOS color camera
- Earphone camera

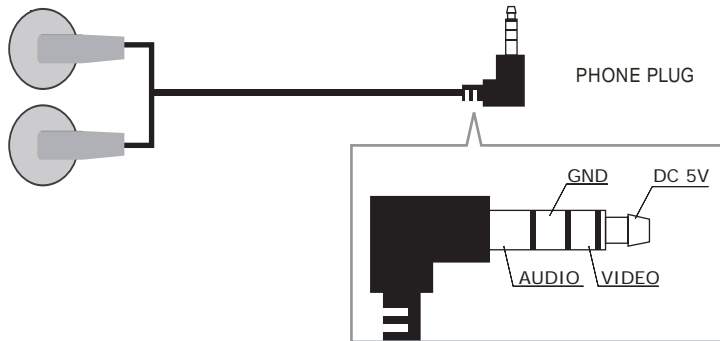

Optional accessory



AF-225

Application



Everyone will just assume you listening to your MP3 player one of the earphones is a hidden camera one of the earphones is a hidden microphone Ideal for security or covert applications Will easily integrate with a camcorder or mini portable DVR

Specification

Model	MJ-P260
Video system	NTSC / PAL
Number of effective pixels	510 x 492 (NTSC) , 628 x 582(PAL)
Image sensor	1/3" CCIQ Color Camera
Resolution(TV Lines)	380 TV Lines
S/N Ratio	more than 48dB
Minimum illumination	0.2 LUX / F1.2
Electronic shutter	1/50-1/12,5000 Sec
Horizontal sync frequency	NTSC(EIA) -15.734kHz , PAL(CCIR) - 15.625kHz
Vertical sync frequency	NTSC(EIA) - 60Hz , PAL(CCIR) - 50Hz
Camera consumption	0.45
Video output	1Vp-p , 75ohm composite
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Built-in Lens	3.9mm F3.9 Pin hole lens
Power source	DC 5-12 V(Standard)
Power current	60 mA

Order information

TYPE	LENS	Electronic Shutter
MJ-P260	3.9mm / F3.9	1/50-1/125,000
MJ-P260Y	3.9mm / F3.9 (DAY AND NIGHT)	1/50-1/125,000



MP-415E



MP-469E