


Specification

MODEL	FOCAL LENGTH	FILTER	THREAD PITCH	ACCESSORIES
LPK8324IR-12	8.3mm /F2.4	IR Filter	M12 x P0.5	With hidden lens Cover (7 Type) Changeable
LPK4320IR-12	4.3mm /F2.0	IR Filter	M12 x P0.5	
LPK3320IR-12	3.3mm /F2.0	IR Filter	M12 x P0.5	
LPK8324IR-10	8.3mm /F2.4	IR Filter	M10 x P0.5	
LPK4320IR-10	4.3mm /F2.0	IR Filter	M10 x P0.5	
LPK3320IR-10	3.3mm /F2.0	IR Filter	M10 x P0.5	
LPK330IRHD-7 (1mega pixel lens)	3.3mm /F2.0	IR Filter	M7 x P0.5	
LPK4020IR-7	4.0mm /F2.0	IR Filter	M7 x P0.5	
LPK8324IR-7	8.3mm /F2.4	IR Filter	M7 x P0.5	
LPK8324YR-12	8.3mm /F2.4	Day & Night Filter	M12 x P0.5	
LPK4320YR-12	4.3mm /F2.0	Day & Night Filter	M12 x P0.5	
LPK3320YR-12	3.3mm /F2.0	Day & Night Filter	M12 x P0.5	
LPK8324YR-10	8.3mm /F2.4	Day & Night Filter	M10 x P0.5	
LPK4320YR-10	4.3mm /F2.0	Day & Night Filter	M10 x P0.5	
LPK3320YR-10	3.3mm /F2.0	Day & Night Filter	M10 x P0.5	
LPK4020YR-7	4.0mm /F2.0	Day & Night Filter	M7 x P0.5	
LPK330YRHD-7 (1mega pixel lens)	3.3mm /F2.0	Day & Night Filter	M7 x P0.5	
LPK8324YR-7	8.3mm /F2.4	Day & Night Filter	M7 x P0.5	
LPK8324-12	8.3mm /F2.4	AR Filter	M12 x P0.5	
LPK8324-10	8.3mm /F2.4	AR Filter	M10 x P0.5	
LPK4320-10	4.3mm /F2.0	AR Filter	M10 x P0.5	
LPK3320-10	3.3mm /F2.0	AR Filter	M10 x P0.5	
LPK4020-7	4.0mm /F2.0	AR Filter	M7 x P0.5	
LPK8324-7	8.3mm /F2.4	AR Filter	M7 x P0.5	
LPK3320HD-7 (1mega pixel lens)	3.3mm /F2.0	AR Filter	M7 x P0.5	

Instruction Drawing & Description

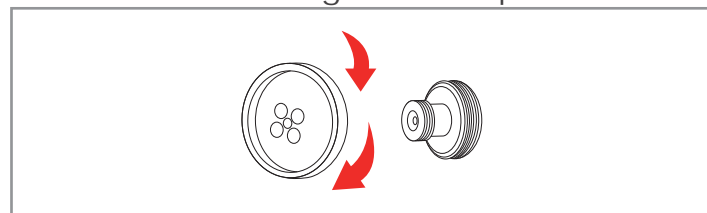

Other Information

