
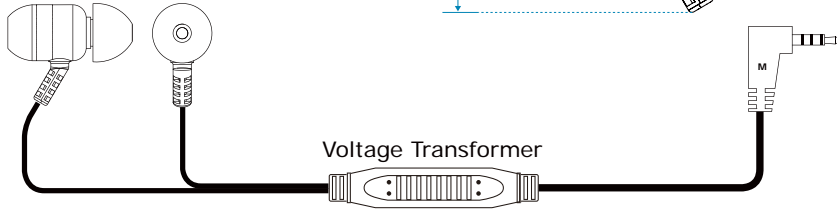


Feature

- CCIQ** ▶ Challenge CCD Image Quality
- Hi Resolution up to 400 TV Lines.
- Earphone Camera
- High Quality Picture.
- High Performance.
- Outstanding Quality!

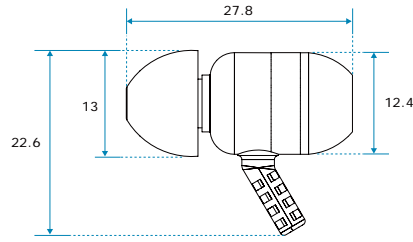

Unit : mm (± 0.5)

Specification

| | | |
|----------------------------|--|---------|
| Model | MJ-P360 | MJ-P366 |
| case | Black | white |
| Video system | NTSC / PAL | |
| Number of effective pixels | 648 x 488(NTSC & PAL) | |
| Image sensor | 1/4" CCIQ II Color Camera | |
| Resolution(TV Lines) | 400 TV Lines | |
| S/N Ratio | more than 48dB | |
| Minimum illumination | 0.1 LUX / F1.2 | |
| Image Transfer Rate | 60 field/sec (NTSC) , 50 field/sec (PAL) | |
| Horizontal sync frequency | NTSC - 15.734kHz , PAL - 15.625kHz | |
| Vertical sync frequency | NTSC - 60Hz , PAL - 50Hz | |
| Camera consumption | 0.45 | |
| Video output | 1Vp-p , 75ohm composite | |
| Audio output | 20-16000Hz,S/N more than 58dB (Optional) | |
| Storage temperature | -30 to 60 Degree C | |
| Working temperature | -10 to 45 Degree C | |
| Built-in Lens | 3.9 mm/F3.9 | |
| Power source | DC 5 - 12 V(Standard) | |
| Power current | 50 mA | |



▲ MJ-P360



▲ MJ-P366



Earphone Camera

Ordering information

| MODEL | CONNECT | PITCHER |
|----------------|---------|---------|
| MQ-P360 | | |
| JO-P360 | | |
| MJ-P360 | | |
| MQ-P360 | | |

NOTE :
G : GND **P** : DC POWER
A : AUDIO **V** : VIDEO

Optional accessories

AF-225

MS-9104

Other Information

MP-469E
 Mobile Digital Video Recorder
 MINI Mobile Digital Video Recorder
 SD/MMC, Card Slot (support up to 4GB SDHC)
 MPEG 4 REC Video & Snapshot JPG Image

