


**Feature**

- CCIQ** ▶ Challenge CCD Image Quality
- Hi Resolution up to 400 TV Lines.
- Earphone Camera
- High Quality Picture.
- High Performance.
- Outstanding Quality!

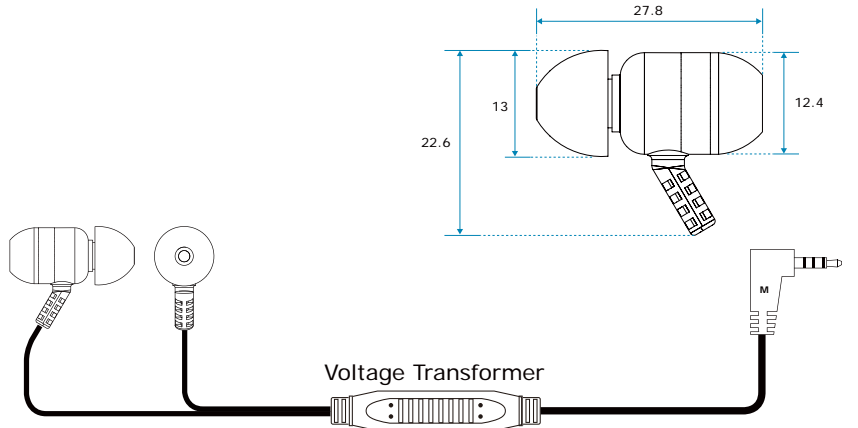

Unit : mm (± 0.5)

**Specification**

Model	MJ-P460	MJ-P466
case	Black	white
Video system	NTSC / PAL	
Number of effective pixels	648 x 488(NTSC & PAL)	
Image sensor	1/4" CCIQ II Color Camera	
Resolution(TV Lines)	400 TV Lines	
S/N Ratio	more than 48dB	
Minimum illumination	0.1 LUX / F1.2	
Image Transfer Rate	60 field/sec (NTSC) , 50 field/sec (PAL)	
Horizontal sync frequency	NTSC - 15.734kHz , PAL - 15.625kHz	
Vertical sync frequency	NTSC - 60Hz , PAL - 50Hz	
Camera consumption	0.45	
Video output	1Vp-p , 75ohm composite	
Audio output	20-16000Hz,S/N more than 58dB (Optional)	
Storage temperature	-30 to 60 Degree C	
Working temperature	-10 to 45 Degree C	
Built-in Lens	3.9 mm/F3.9	
Power source	DC 5 - 12 V(Standard)	
Power current	50 mA	



▲ MJ-P460



▲ MJ-P466



**Earphone Camera**

**Ordering information**

MODEL	CONNECT	PITCHER
<b>MQ-P460</b>		
<b>JO-P460</b>		
<b>MJ-P460</b>		
<b>MQ-P460</b>		

NOTE :  
**G** : GND      **P** : DC POWER  
**A** : AUDIO     **V** : VIDEO

**Optional accessories**

**AF-225**

**MS-9104**

**Other Information**

**MP-469E**  
 Mobile Digital Video Recorder  
 MINI Mobile Digital Video Recorder  
 SD/MMC. Card Slot (support up to 4GB SDHC)  
 MPEG 4 REC Video & Snapshot JPG Image

