 
 



(BOARD TYPE)MO-B3506




(Tube type)MO-T3506LW



 (Tube Type)MO-T3575LW




MO-T3506LC

 

MO-L3506



 MO-L3575



unit : mm (±0.5)

Feature

- Ø 7.7 mm Only
- Compact size.
- Backlight compensation.
- High Quality Picture.
- High Performance.
- Outstanding Quality!
- Competitive Price!


Specification

| Model | MO-T3506 | MO-T3575 |
|----------------------------|----------------------------------|---------------|
| LED Light | LED x 4 Pcs | |
| Video system | NTSC & PAL | |
| Number of effective pixels | 648 x 488 | |
| Image sensor | 1/4" Color CCIQ II Camera | |
| Resolution(TV Lines) | 400 TV Lines | |
| S/N Ratio | more than 50dB | |
| Minimum illumination | 0.1LUX / F1.2 | |
| Image Transfer Rate | 60 fps | |
| Horizontal sync frequency | NTSC - 15.734kHz , PAL-15.625KHz | |
| Vertical sync frequency | NTSC - 60Hz , PAL-50Hz | |
| Camera consumption | 0.45 | |
| Video output | 1Vp-p , 75ohm composite | |
| Built - in Lens | 3.1mm/F3.4 | |
| Storage temperature | -30 to 60 Degree C | |
| Working temperature | -10 to 45 Degree C | |
| Power source | DC 4~12 V(Standard) | |
| Power current | 100 mA | |
| Dimension (mm) | Ø 8 x 12(mm) | Ø 12 x 25(mm) |

MO-B3506(Board only) — MO-B3506(With 3T Lens)



(Tube-Type)MO-L3506 — MO-T3506LW

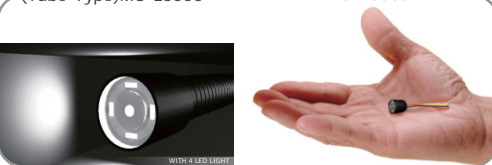

(Tube-Type)MO-L3575



Ordering information

| MODEL | MODULE TYPE | DIMENSION (mm) | LED | CONNECT |
|------------|-------------------|----------------|------------------|-------------------------|
| MO-B3506 | BOARD TYPE MODULE | Ø 7.7 (mm) | X | 3 WIRE OUT |
| MO-T3506W | TUBE TYPE MODULE | Ø 8 (mm) | X | 3 WIRE OUT |
| MO-T3506C | TUBE TYPE MODULE | Ø 8 (mm) | X | TUBE TYPE CABLE OUT |
| MO-T3506LW | TUBE TYPE MODULE | Ø 8 (mm) | WITH LED x 4 Pcs | 3 WIRE OUT |
| MO-T3506LC | TUBE TYPE MODULE | Ø 8 (mm) | WITH LED x 4 Pcs | TUBE TYPE CABLE OUT |
| MO-R3506 | SNAKE TYPE MODULE | Ø 8 (mm) | X | SNAKE TYPE DC IN RCA IN |
| MO-L3506 | SNAKE TYPE MODULE | Ø 8 (mm) | WITH LED x 4 Pcs | SNAKE TYPE DC IN RCA IN |
| MO-T3575W | TUBE TYPE MODULE | Ø 12 (mm) | X | 3 WIRE OUT |
| MO-T3575C | TUBE TYPE MODULE | Ø 12 (mm) | X | TUBE TYPE CABLE OUT |
| MO-T3575LW | TUBE TYPE MODULE | Ø 12 (mm) | WITH LED x 4 Pcs | 3 WIRE OUT |
| MO-T3575LC | TUBE TYPE MODULE | Ø 12 (mm) | WITH LED x 4 Pcs | TUBE TYPE CABLE OUT |
| MO-R3575 | SNAKE TYPE MODULE | Ø 12 (mm) | X | SNAKE TYPE DC IN RCA IN |
| MO-L3575 | SNAKE TYPE MODULE | Ø 12 (mm) | WITH LED x 4 Pcs | SNAKE TYPE DC IN RCA IN |

NOTE :

MO-T3506W **W**: 3 WIRE

MO-T3506C **C**: CABLE(OD 1.9mm , cable out : 75cm)

MO-L3506 **L**: Snake camera with Handle Bar