


## Feature

- SDHC /SD card slot (support up to 32GB)
- Built-in flash memory 128 MB
- Snapshot
- Image 640 x 480(JPG)
- High Performance.
- Date and Time
- Competitive Price!

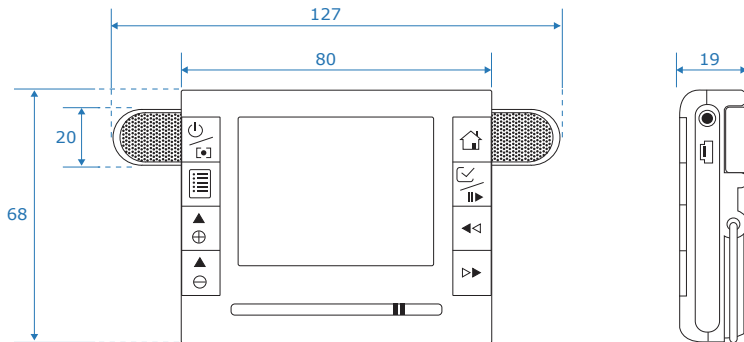

unit : mm (±0.5)

## Specification

Model	MP-455E
Display	2.5" LTPTS TFT LCD 508x240(230K)
External Memory	SDHC /SD card slot (support up to 32GB) , Built-in flash memory 128 MB
Interface	2 in 1 MiniUSB ( USB2.0 / Power in ) ; 4 in 1 earphone jack (Video out / earphone jack / external microphone / AV in)
Video out / Video in	TV OUT ( NTSC / PAL ) / AV IN ( NTSC / PAL )
Function	Snapshot(640 x 480-jpg ) Timebar Scheduled recording function ( 12 event ) Special Power save button (monitor sleep mode)
Extend interface	Extend DC power 9V out for camera and AV in
AV recorder resolution	640 x 480 (VGA) / max 30 fps
AV audio quality	2 modes : radio quality (16KHz) / CD quality (48KHz)
AV recorder quality	MPEG4 : best fine normal basic economy
Voice recorder	2 modes: radio quality (16KHz)/CD quality (48KHz)
Format support	JPEG ASF WAV MP3 WMA
Language support	12 languages: English, German, French, Spanish, Italian, Portuguese , Japanese, simple Chinese, tradition Chinese, Korean, Polish, Turkey
Battery	Rechargeable LI-ION battery(3.7 V /920mA , compatible with NP60 type battery)
Adapter	5V DC adapter (USB port) / USB cable
Weight(g)	95g ( with battery)
Size	18 x 68 x 81 ( L x W x H ) mm



MP-455E

## Ordering information

