


Specification

Model	MP-500
AV recorder resolution	640x480(VGA) / max 30 fps.
External Memory	SD Card memory slot (support up to 16 GB)
Compression	MPEG 4 ASF file
Video	Synchronized audio & video recording/ playback
Video Output	TV out /AV in (NTSC/PAL)
Function	AV In Mode , Rec Mode , Play Mode , PreviewOSD displaying icons , SD card Update , ISP Mode , Special circumstances
PC Interface	USB1.1
Dimension	32 x 68 mm



MP-500

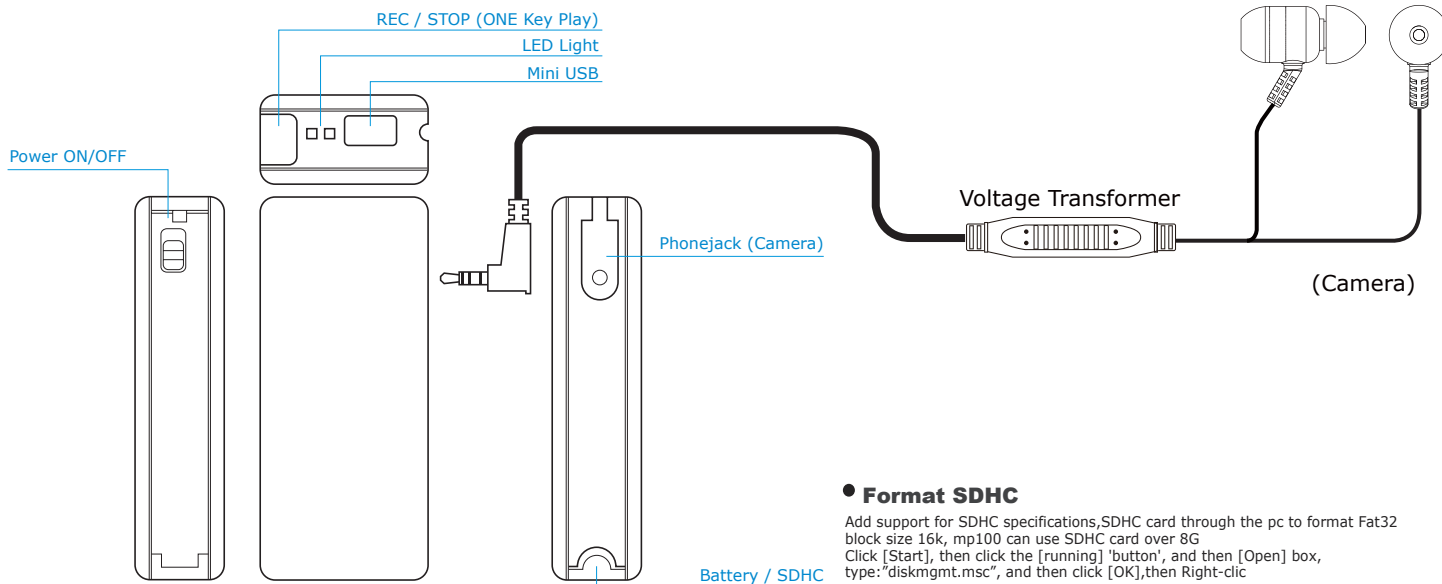

● **Format SDHC**

Add support for SDHC specifications,SDHC card through the pc to format Fat32 block size 16k, mp100 can use SDHC card over 8G
Click [Start], then click the [running] 'button', and then [Open] box, type:"diskmgmt.msc", and then click [OK],then Right-click

Other Information

MJ-P360

Earphone camera (CCIQ II)



MJ-P366

Earphone camera (CCIQ II)



MJ-3501

1/4" Color CCIQ II Headset Camera
Built-in Microphone



Ultra Mini Wearable Camera

1/4" Color CCIQ II Camera
Video out: TV out playback

