



**SPY CAMERA**

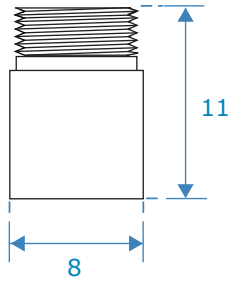

Unit : mm (± 0.5)

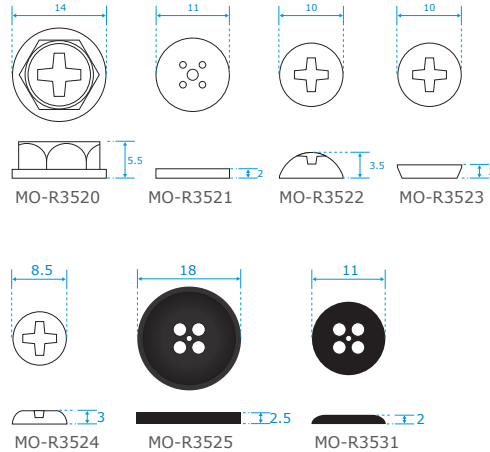

**Feature**

- CCIQ II** ▶ Challenge CCD Image Quality
- Hi Resolution up to 400 TV Lines.
- Compact size.
- Backlight compensation.
- High Quality Picture.
- High Performance.
- Outstanding Quality!
- Competitive Price!

**Specification**

Model	MO-R3520	MO-R3521	MO-R3522	MO-R3523	MO-R3524	MO-R3525	MO-R3531
Video system	NTSC / PAL						
Number of effective pixels	648 x 488						
Image sensor	1/4" CCIQ II Color Camera						
Resolution(TV Lines)	400 TV Lines						
S/N Ratio	more than 50dB						
Minimum illumination	0.1 LUX / F1.2						
Electronic shutter	60 field/sec (NTSC) , 50 field/sec (PAL)						
Horizontal sync frequency	NTSC(EIA) -15.734kHz , PAL(CCIR) - 15.625kHz						
Vertical sync frequency	NTSC(EIA) - 60Hz , PAL(CCIR) - 50Hz						
Camera consumption	0.45						
Video output	1Vp-p , 75ohm composite						
Storage temperature	-30 to 60 Degree C						
Working temperature	-10 to 45 Degree C						
Built-in Lens	3.1mm/F3.4						
Power source	DC 5~12 V(Standard)						
Power current	50 mA-Max (DC 12V)						
Lens Cover	Screw	Button	Screw	Screw	Screw	Button	Button
Dimension (mm)	8 x 11 (mm)						



**Ordering Information**

Model	Lens Cover	Mic.	Model	Lens Cover	Mic.
MO-R3520	Screw	x	MO-R3520A	Screw	External
MO-R3521	Button	x	MO-R3521A	Button	External
MO-R3522	Screw	x	MO-R3522A	Screw	External
MO-R3523	Screw	x	MO-R3523A	Screw	External
MO-R3524	Screw	x	MO-R3524A	Screw	External
MO-R3525	Button	x	MO-R3525A	Button	External
MO-R3531	Button	x	MO-R3531A	Button	External

**Note:**

MO-R3520Y : Y : Day & Night

**Other information**

**CCD HIDDEN CAMERA ▶ MO-N35310**

**SPY CAMERA ▶ NX-C8XX**

1/4" COLOR CCD CAMERA  
410K(PAL),380K(NTSC)  
W/ 4.3mm/F2.0(ø10XP0.5) (TOP ø7)LENS

