 
 



(BOARD TYPE)MO-B3506




(Tube type)MO-T3506LW



 (Tube Type)MO-T3575LW




MO-T3506LC

 

MO-L3506



 MO-L3575



unit : mm (±0.5)

Feature

- Ø 7.7 mm Only
- Compact size.
- Backlight compensation.
- High Quality Picture.
- High Performance.
- Outstanding Quality!
- Competitive Price!


Specification

Model	MO-T3506	MO-T3575
LED Light	LED x 4 Pcs	
Video system	NTSC & PAL	
Number of effective pixels	648 x 488	
Image sensor	1/4" Color CCIQ II Camera	
Resolution(TV Lines)	400 TV Lines	
S/N Ratio	more than 50dB	
Minimum illumination	0.1LUX / F1.2	
Image Transfer Rate	60 field/sec (NTSC) , 50 field/sec (PAL)	
Horizontal sync frequency	NTSC -15.734kHz , PAL-15.625KHz	
Vertical sync frequency	NTSC - 60Hz , PAL-50Hz	
Camera consumption	0.45	
Video output	1Vp-p , 75ohm composite	
Built - in Lens	3.1mm/F3.4	
Storage temperature	-30 to 60 Degree C	
Working temperature	-10 to 45 Degree C	
Power source	DC 4~12 V(Standard)	
Power current	100 mA	
Dimension (mm)	Ø 8 x 12(mm)	Ø 12 x 25(mm)

MO-B3506(Board only) — MO-B3506(With 3T Lens)



(Tube-Type)MO-L3506 — MO-T3506LW

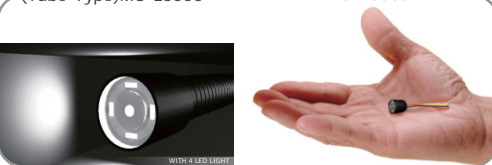

(Tube-Type)MO-L3575



Ordering information

MODEL	MODULE TYPE	DIMENSION (mm)	LED	CONNECT
MO-B3506	BOARD TYPE MODULE	Ø 7.7 (mm)	X	3 WIRE OUT
MO-T3506W	TUBE TYPE MODULE	Ø 8 (mm)	X	3 WIRE OUT
MO-T3506C	TUBE TYPE MODULE	Ø 8 (mm)	X	TUBE TYPE CABLE OUT
MO-T3506LW	TUBE TYPE MODULE	Ø 8 (mm)	WITH LED x 4 Pcs	3 WIRE OUT
MO-T3506LC	TUBE TYPE MODULE	Ø 8 (mm)	WITH LED x 4 Pcs	TUBE TYPE CABLE OUT
MO-R3506	SNAKE TYPE MODULE	Ø 8 (mm)	X	SNAKE TYPE DC IN RCA IN
MO-L3506	SNAKE TYPE MODULE	Ø 8 (mm)	WITH LED x 4 Pcs	SNAKE TYPE DC IN RCA IN
MO-T3575W	TUBE TYPE MODULE	Ø 12 (mm)	X	3 WIRE OUT
MO-T3575C	TUBE TYPE MODULE	Ø 12 (mm)	X	TUBE TYPE CABLE OUT
MO-T3575LW	TUBE TYPE MODULE	Ø 12 (mm)	WITH LED x 4 Pcs	3 WIRE OUT
MO-T3575LC	TUBE TYPE MODULE	Ø 12 (mm)	WITH LED x 4 Pcs	TUBE TYPE CABLE OUT
MO-R3575	SNAKE TYPE MODULE	Ø 12 (mm)	X	SNAKE TYPE DC IN RCA IN
MO-L3575	SNAKE TYPE MODULE	Ø 12 (mm)	WITH LED x 4 Pcs	SNAKE TYPE DC IN RCA IN

NOTE :

 
 
MO-T3506W W: 3 WIRE

MO-T3506C C: CABLE(OD 1.9mm , cable out : 75cm)

MO-L3506 L: Snake camera with Handle Bar

Feature


- Automatic Image Control
- Backlight Compensation.
- High Quality Picture.
- High Performance.
- Outstanding Quality!
- Focal Distance 5cm
- With LED Light



unit : mm (±0.5)

Specification

Model	MO-L3509
Video system	NTSC / PAL
Number of effective pixels	648 x 488
Image sensor	1/4" Color CCIQ II Camera
Resolution(TV Lines)	400 TV Lines
S/N Ratio	more than 50dB
Minimum illumination	0.1 LUX / F1.2
Electronic shutter	60 field/sec (NTSC) , 50 field/sec (PAL)
Horizontal sync frequency	NTSC(EIA) - 15.734kHz , PAL(CCIR) - 15.625kHz
Vertical sync frequency	NTSC(EIA) - 60Hz , PAL(CCIR) - 50Hz
Camera consumption	0.45
Video output	1Vp-p , 75ohm composite
Built - in Lens	3.1 mm / F2.0
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Power source	DC 5 - 12 V
Power current	120 mA
Dimension (mm)	Ø 9.1 x 41 (mm)

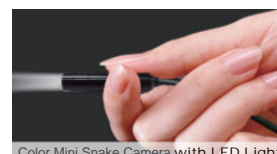

Color Mini Snake Camera with LED Light

▲ MO-T3509LBC



▲ MO-L3509

Ordering Information

MODEL	LENS	LED LIGHT ILLUMINATION	NOTE
MO-L3509-3T	3.1mm / F3.4	5400 LUX	SNAKE TYPE DC IN RCA IN
MO-L3509-4T	3.9mm / F3.9	5400 LUX	SNAKE TYPE DC IN RCA IN
MO-L3509-8F	8.3mm / F2.4	5400 LUX	SNAKE TYPE DC IN RCA IN
MO-T3509BC-3T	3.1mm / F3.4	X	Cable Out
MO-T3509BC-4T	3.9mm / F3.9	X	Cable Out
MO-T3509BC-8F	8.3mm / F2.4	X	Cable Out
MO-T3509LBC-3T	3.1mm / F3.4	5400 LUX	Cable Out
MO-T3509LBC-4T	3.9mm / F3.9	5400 LUX	Cable Out
MO-T3509LBC-8F	8.3mm / F2.4	5400 LUX	Cable Out

Other Information

MO-L805

1/18" Color CMOS Camera
With LED x 2 light source

 


UNIT:mm



MO-L3575

1/4" Color CCIQ II Camera
With LED light source



UNIT:mm

