


**Monitor Module**

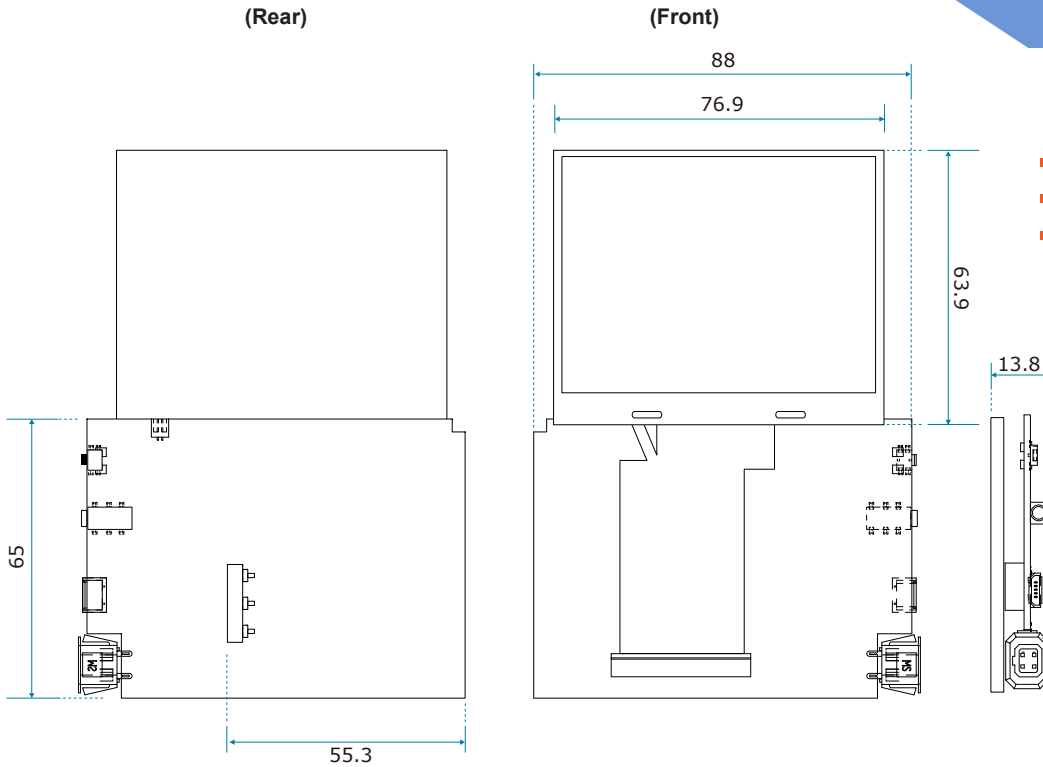

**Feature**

- 3.5" TFT
- Audio output
- 6 LED serial

Unit : mm (± 0.5)

**Specification**

MODEL	MS-M350M
Display	3.5" TFT
Color Depth	24bit
Pixel pitch (mm)	0.219mm x 0.219mm
Active Area(mm)	70.08mm x 52.56mm
Display colors	16.7M dithering
LED Numbers	6 LED Serial
Power charge Interface	micro USB 2.0
Power charge	DC 5V (450 mA)
Battery	rechargeable Li-ion battery NP120 (2000mAh)



MS-M350M

**Instruction Drawing & Description**

