



UCD-210

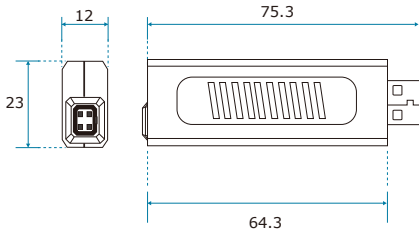

UCD-210M

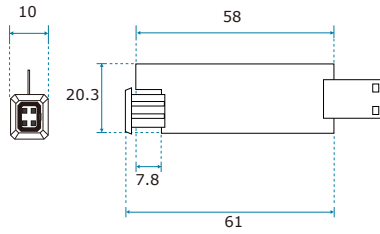

Unit : mm (± 0.5)

Feature

- No driver install (USB Video Class)
- A/V CVBS NTSC / PAL input
- Play & Plug with USB Video Class
- Live video calls with MSN Messenger、SKYPE and YouTube
- Build in 3D comb filter and 3D de-interlace
- Compact size perfect for travel and portable use.

Specification

Model	UCD-210	UCD-210M
Frame rate	NTSC for 30fps / PAL for 25fps	
Resolution	NTSC / PAL: 640 x 480	
Video format	MJPEG	
Interface	USB 2.0	
Storage temperature	-30 to 60 Degree C	
Working temperature	-10 to 45 Degree C	
OS support	windows XP、Vista、win7, Linux any version, MAC OS	
Power Input	DC 5V(240mA)	
Dimension	64.3 (L) x 12 (H) x 23 (W) m	58 (L) x 10 (H) x 20.3 (W) mm

- Driver free (USB Video Class) for any OS (windows XP、Vista、win7, Linux any version, MAC OS)
- A/V CVBS NTSC / PAL input
- Play & Plug with USB Video Class
- Live video calls with MSN Messenger、SKYPE、YouTube and JoinNet
- Available USB 2.0 port
- Build in 3D comb filter and 3D de-interlace
- Compact size perfect for travel and portable use.




UCD-210



UCD-210M

Instruction Drawing & Description

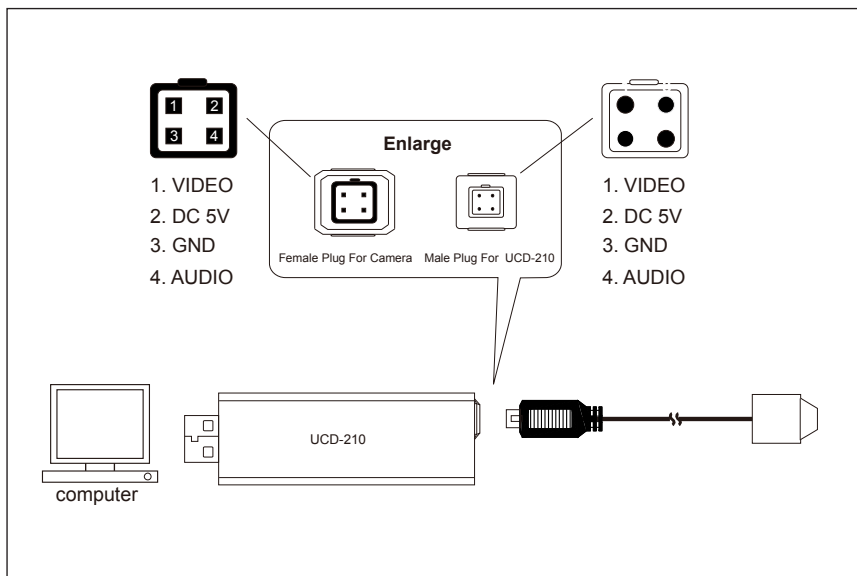

Model	Resolution	NOTE
UCD-210	640 x 480 (NTSC / PAL)	UCD-210M M: Module only
UCD-210HN	720 x 480 (NTSC only)	
UCD-210HP	720 x 576 (PAL/secam only)	
UCD-210M	640 x 480 (NTSC / PAL)	
UCD-210MHN	720 x 480 (NTSC only)	
UCD-210MHP	720 x 576 (PAL/secam only)	

other information

USB Video Capture Devices ▶ UCD-110

Captures video at resolutions up to 720 x 480 (NTSC) or 720 x 576 (PAL)
Capture VIDEO from any SPY Camera to your computer hard drive
Connects to Windows XP machines USB 2.0 port
Integrated input connections with mini 4 pin

