



Feature

- High Sensitivity!
- with 3M double-sided tape easy installation
- Dimension :26.4x 9.2 mm
- Compact size

MS-6200
MS-6200ALC

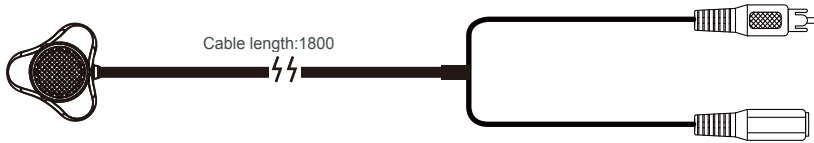

 MS-6200PC



unit : mm (±0.2)



Specification

Model	MS-6200	MS-6200PC	MS-6200ALC
Frequency	20-16000Hz		
S/N Ratio	More than 58dB		
Impedance	600 ohm +/- 20% (at 1000Hz)		
Power Source	DC 12V	/	DC 12V
S/N Ratio	20mA(max)		20mA(max)
Dimension	26.4 x 9.2 mm		
Note	normal	PC mic.	ALC function (automatic level control)



MS-6200

Other information

MS-3500

- GAIN CONTROL VALUE CHANGEABLE

Frequency: 20 -16000Hz
S/N Ratio: more than 58dB
Impedance: 150 ohms ±20%(at 1000 Hz)
Sensitivity: -44dB ±3dB(at 1,000Hz)
Dimension : 6X18X4 mm



MS-6300W

- MINI MICROPHONE

Frequency: 20 -16000Hz
S/N Ratio: more than 58dB
Impedance: 150 ohms ±20%(at 1000 HZ)
Power : DC 7~12V
Dimensions: 6x18x3.5 mm

