



Body Type

optical panel(OP-100-01)/front

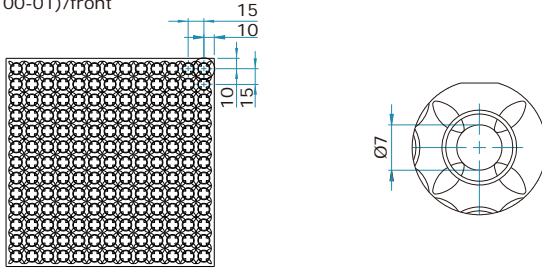


optical panel(OP-100-01)/rear

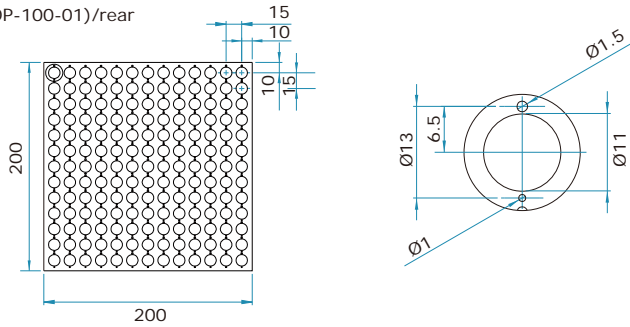


Feature

- High Sensitivity!
- High Performance.
- Memory size UP TO 16 K
- 550 TV lines
- Easy install

camera(MO-EZ05-3G)

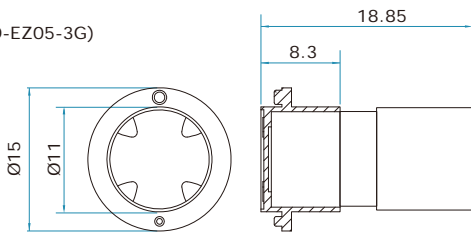

camera(MO-EZ06-3G)

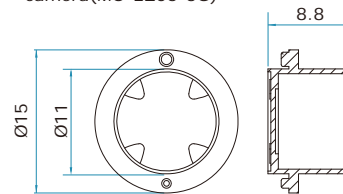

unit : mm (±0.5)

Specification

Model	MO-EZ05-3G	MO-EZ06-3G
Video system	EIA / CCIR	
Number of effective pixels	728(H) x 488(V) (EIA & CCIR)	648(H) x 488(V) (EIA & CCIR)
Image sensor	1/3" CCIQ III B/W Camera	1/4" CCIQ III B/W Camera
Resolution(TV Lines)	550 TV Lines	
S/N Ratio	46.4 dB	47.0 [dB]
Max Dynamic Range	63.7 [dB]	63.3 [dB]
Sensor scan mode	progressive scan	
Minimum illumination	0.05Lux /F 1.2 20IRE	0.006Lux /F 1.2 20IRE
Frame Rate	60 field/sec(EIA), 50 field/sec(CCIR) CVBS	
Sensitivity	13.8 [V/Lux.sec]	8.2 [V/Lux.sec]
Horizontal sync frequency	EIA -15.734kHz , CCIR - 15.625kHz	
Vertical sync frequency	EIA - 60Hz , CCIR - 50Hz	
Camera consumption	0.45	
Video output	1Vp-p , 75ohm composite	
Built-in Lens	3.6mm/ F2.0	
Storage temperature	-30 to 60 Degree C	
Working temperature	-10 to 45 Degree C	
Power source	Camera input: DC 5 - 12V	
Power current	80 mA(max)-DC12V	




+



MO-EZ05

Ordering information

• How to install

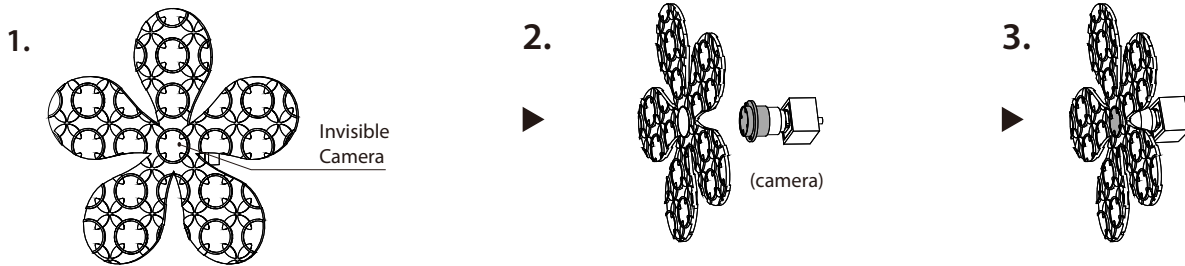

Easy install! Hidden camera can be installed on any hole you drilled on the pc board.

PC board can be cut into customized shape by customer request











• To be installed IR 940nm LED light by customer request.

To easily provides the ability to see in low light conditions.(ordering in advance)



Body Type

	Model	NOTE	DIMENSION (mm)
 camera + optical panel (OP-100-01)	MO-EZ05	1/3" B/W CCIQ III SPY Mini Concealed Camera kit	Camera: $\varnothing 15 \times 18.8$ mm Optical panel: 200 x 200 mm
	MO-EZ05A	1/3" B/W CCIQ III SPY Mini Concealed Camera kit + external microphone	
	MO-EZ055	1/3" Color CCIQ III SPY Mini Concealed Camera kit	
	MO-EZ055A	1/3" Color CCIQ III SPY Mini Concealed Camera kit + external microphone	
 camera + optical panel (OP-100-01)	MO-EZ06	1/4" B/W CCIQ III SPY CSM Mini Concealed Camera kit	Camera: $\varnothing 15 \times 8.8$ mm Optical panel: 200 x 200 mm
	MO-EZ06A	1/4" B/W CCIQ III SPY CSM Mini Concealed Camera kit + external microphone	
	MO-EZ066	1/4" Color CCIQ III SPY CSM Mini Concealed Camera kit	
	MO-EZ066A	1/4" Color CCIQ III SPY CSM Mini Concealed Camera kit + external microphone	
 camera + optical panel (OP-100-01) 15fps (super low light)	MX-EZ57K	1/3.7" B/W CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MX-EZ57KA	1/3.7" B/W CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit + external microphone	
	MX-EZ55K	1/3.7" Color CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MX-EZ55KA	1/3.7" Color CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit + external microphone	
	MX-EZ59K	1/4" B/W CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MX-EZ59KA	1/4" B/W CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit + external microphone	
	MX-EZ56K	1/4" Color CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MX-EZ56KA	1/4" Color CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit + external microphone	
 camera + optical panel (OP-100-01) 15fps (super low light)	MX-EZ57KS	1/3.7" B/W CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	Camera: $\varnothing 15 \times 9$ mm Optical panel: 200 x 200 mm
	MX-EZ55KS	1/3.7" Color CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MO-EZ05C	1/3" B/W CCIQ III SPY Mini Concealed Camera	$\varnothing 15 \times 18.8$ mm
	MO-EZ055C	1/3" Color CCIQ III SPY Mini Concealed Camera	
	MO-EZ06C	1/4" B/W CCIQ III SPY CSM Mini Concealed Camera	$\varnothing 15 \times 8.8$ mm
	MO-EZ066C	1/4" Color CCIQ III SPY CSM Mini Concealed Camera	
 15fps (super low light)	MX-EZ57KC	1/3" B/W CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MX-EZ55KC	1/3" Color CCIQ III SPY Hybrid Sensitivity Mini Concealed Camera kit	
	MX-EZ59KC	1/4" B/W CCIQ III SPY Hybrid Sensitivity CSM Mini Concealed Camera	
	MX-EZ56KC	1/4" Color CCIQ III Hybrid Sensitivity SPY CSM Mini Concealed Camera	
 15fps (super low light)	MX-EZ57SKC	1/4" B/W CCIQ III SPY Hybrid Sensitivity Slim Concealed Camera	
	MX-EZ55SKC	1/4" Color CCIQ III SPY Hybrid Sensitivity Slim Concealed Camera	
	OPC-100	Optical camera cap only	$\varnothing 15$ mm / top $\varnothing 11$ mm
	OPI-100S	with IR 940nm LED	
	OP-100	Optical panel	200 x 200 mm
	OP-100-01	Optical panel -one hole drilled	200 x 200 mm
	OP-101-01	Optical panel -customized shape	
	OPI-100M	LED power control board with CDS function	