

Unit : mm (± 0.5)

### Feature

- IR Remote control
- RTC Date and Time Stamping
- Schedule Record
- Overwrite
- 2.5" TFT (648x480 pixels-H.264)
- NP-60 Detachable Battery / Rechargeable
- Power saving
- LCD display on/ off


### Specification

MODEL	MP-400E
Display	2.5" TFT
External	MemorySD Card memory slot (support SDHC, 128G)
Resolution	VGA, 30fps real time recording
Compression	H.264 REC D1 720x480 VIDEO & Snapshot JPG IMAGE
Video	Synchronized audio & video recording/ playback
Function	Date Time stamp function Power saving Low power alert LCD display on/ off Schedule recording Overwrite function IR Remote control
PC Interface	USB2.0
INPUT	2.5mm PHONE JACK Direct supply DC Power 5V output for Camera and Video composite input.
OUTPUT	3.5mm PHONE JACK VIDEO AUDIO composite output
Power Charge	5V DC adapter (USB port) / USB cable
Li-ion battery	NP-60 (1030mAh)
Video Output	NTSC/ PAL auto-detection
Dimension	63.5 (L) x 95.5 (H) x 21 (W) mm



MP-400E

### Instruction Drawing & Description

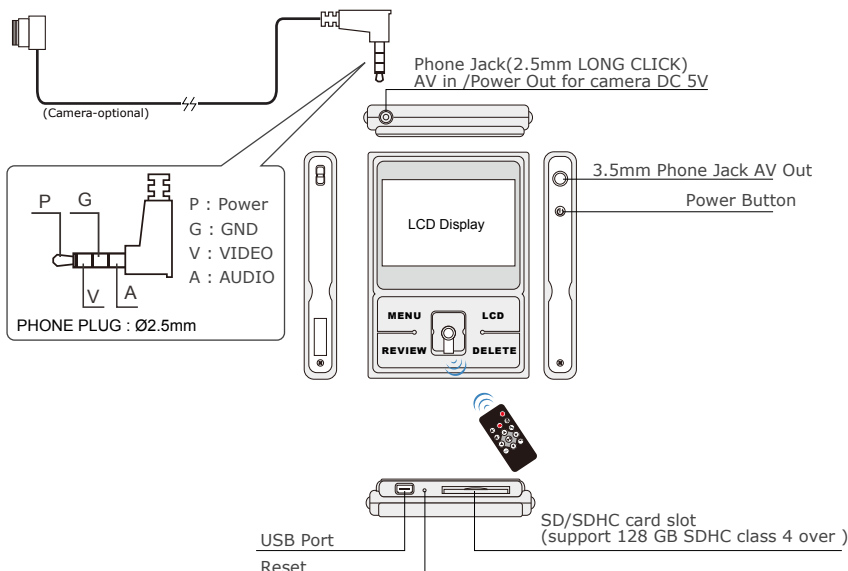

### Other Information

#### MO-L3575V (VCM Lens) with LED light

Electronic MF(Focus adjustable )  
Composite Video Out  
1/4" Color Camera  
Pixel : 648 x 488 ( N / P )  
Dimension : (D)12.6 x 20 (mm)

