


UNIT:±0.5mm

Specification

Features:	<ul style="list-style-type: none"> Connects to Windows XP machines USB 2.0 port TCP Video MJPEG stream 1280 x 720 /YUV 10fps/ MJPEG 30fps/ H.264 24fps 640 x 480 /30 fps 320 x 200 /30 fps Driver free (USB Video Class) for any OS (windows XP Linux any version, MAC OS)
Number of effective pixels	<ul style="list-style-type: none"> 1280 x 720 /YUV 10fps/ MJPEG 30fps/ H.264 24fps 640 x 480 /30 fps 320 x 200 /30 fps
pixel size	3 umx3 um
Image sensor	1/4" WXGA HD 720P Camera
Image area	3888 um x 2430 um
S/N Ratio	39 dB
Scan mode	progressive
Sensitivity	3300mV/(Lux)
Dark Current	20 mV/Sec
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Audio Output	20-16000Hz,S/N more than 58dB
Built-in Lens	3.4mm /F2.8
Power source	DC 5V
Power current	150 mA
Dimension(mm)	40.7 x 10.3mm
Audio	Built-in microphone

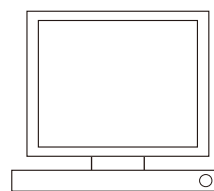

Computer

MODEL	OUTPUT
MD-N40XX	USB 2.0 A type
MM-N40XX	Micro USB OTG B type
MT-N40XX	USB Type-C