


Feature

- Micro USB OTG B type Plug & Play!
- Comfortable to wear, Light weight 55g
- Smart phone connectivity for live stream recording Disaster Rescue Equipment (Earthquake debris, tornado, hurricane, flood, avalanche), Law enforcement

Specification

UNIT:±0.5mm

Features:	<ul style="list-style-type: none"> • Connects to Windows XP machines Micro USB OTG B type port • TCP Video MJPEG stream 1280 x 720 /YUV 10fps/ MJPEG 30fps/ H.264 24fps 640 x 480 /30 fps 320 x 200 /30 fps • Driver free (USB Video Class) for any OS (windows XP Linux any version, MAC OS)
Number of effective pixels	<ul style="list-style-type: none"> • 1280 x 720 /YUV 10fps/ MJPEG 30fps/ H.264 24fps • 640 x 480 /30 fps • 320 x 200 /30 fps
pixel size	3 umx3 um
Image sensor	1/4" WXGA HD 720P Camera
Image area	3888 um x 2430 um
S/N Ratio	39 dB
Scan mode	progressive
Sensitivity	3300mV/(Lux)
Dark Current	20 mV/Sec
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Built-in Lens	3.4mm /F2.8
LED	N/A- Optional
Power source	DC 5V
Power current	150 mA
Dimension(mm)	Ø12.6 x 31mm

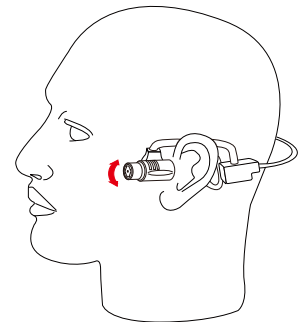

Connector with smart phone or any OTG B type device

Other information

Hi Resolution CCD Helmet Camera ▶ ST-101
 768 x 494 (NTSC) / 752 x 582 (PAL)
 520 TV Lines

OSD Function:
 Camera ID , Image Privacy area , Motion detection ,
 Shutter speed , BLC , AGC , White BAL , H Mirror ,
 Negative Image , RGB Adjust , Gamma ...