

 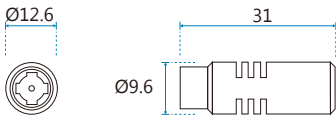


model: **MX-102**

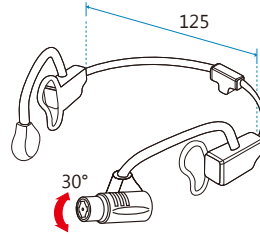

model: **MX-112**




**Feature**

- Micro USB OTG B type Plug & Play!
- Comfortable to wear, Light weight 55g
- Application Possibility: Earthquake debris, tornado, hurricane, flood, avalanche, Law enforcement, so on..

UNIT: ±0.5mm

**Specification**

Model	MX-102	MX-112
Video format	YUV / MJPEG	YUV / MJPEG / H.264
Number of effective pixels	1280 x 720 /YUV 10fps/ MJPEG 30fps 640 x 480 /30 fps 320 x 200 /30 fps	1280 x 720 /YUV 10fps/ MJPEG 30fps/ H.264 24fps 640 x 480 /30 fps 320 x 200 /30 fps
pixel size	3 um x 3 um	
Image sensor	1/4" WXGA HD 720P Camera	
Image area	3888 um x 2430 um	
S/N ratio	39 dB	
Scan mode	progressive	
Sensitivity	3300mV/(Lux)	
Dark current	20 mV/Sec	
Storage temperature	-30 to 60 Degree C	
Working temperature	-10 to 45 Degree C	
Built-in lens	3.4mm /F2.8	
LED	N/A- Optional	
Power source	DC 5V	
Power current	150 mA	
Operating system support	Driver free (USB Video Class) for any OS (windows XP Linux any version, MAC OS )	

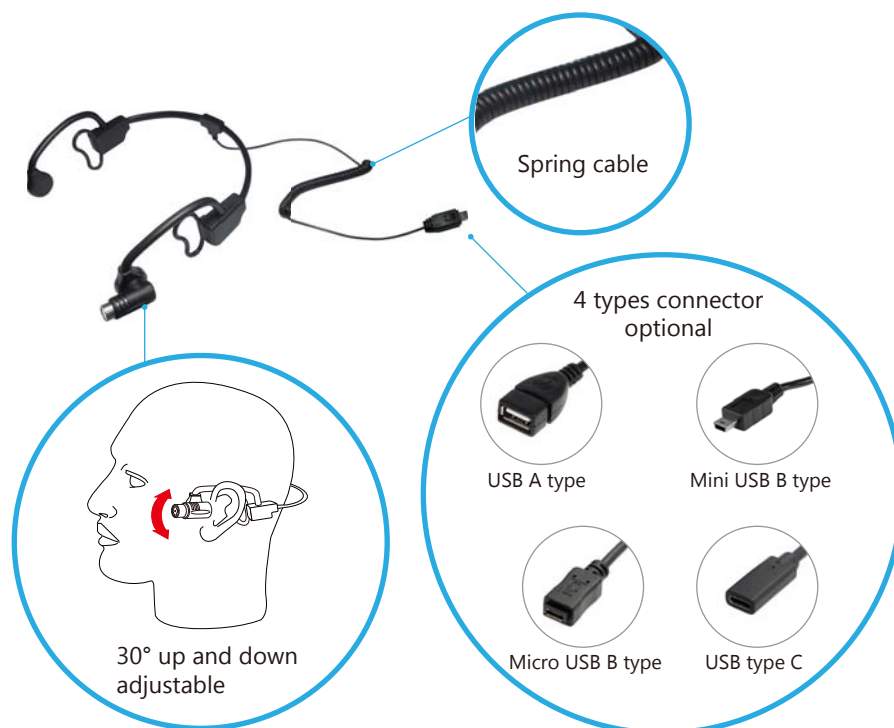

**Model Information**

Model	Connector
MM-102	Micro USB OTG B type
MT-102	USB C type
MD-102	USB 2.0 A type
MI-102	Mini USB B type
MM-112	Micro USB OTG B type
MT-112	USB C type
MD-112	USB 2.0 A type
MI-112	Mini USB B type