
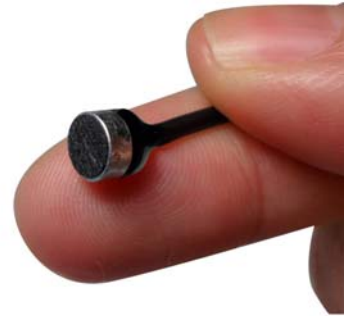


**Feature**

- High Sensitivity!
- Super tiny and power save microphone
- Compact size

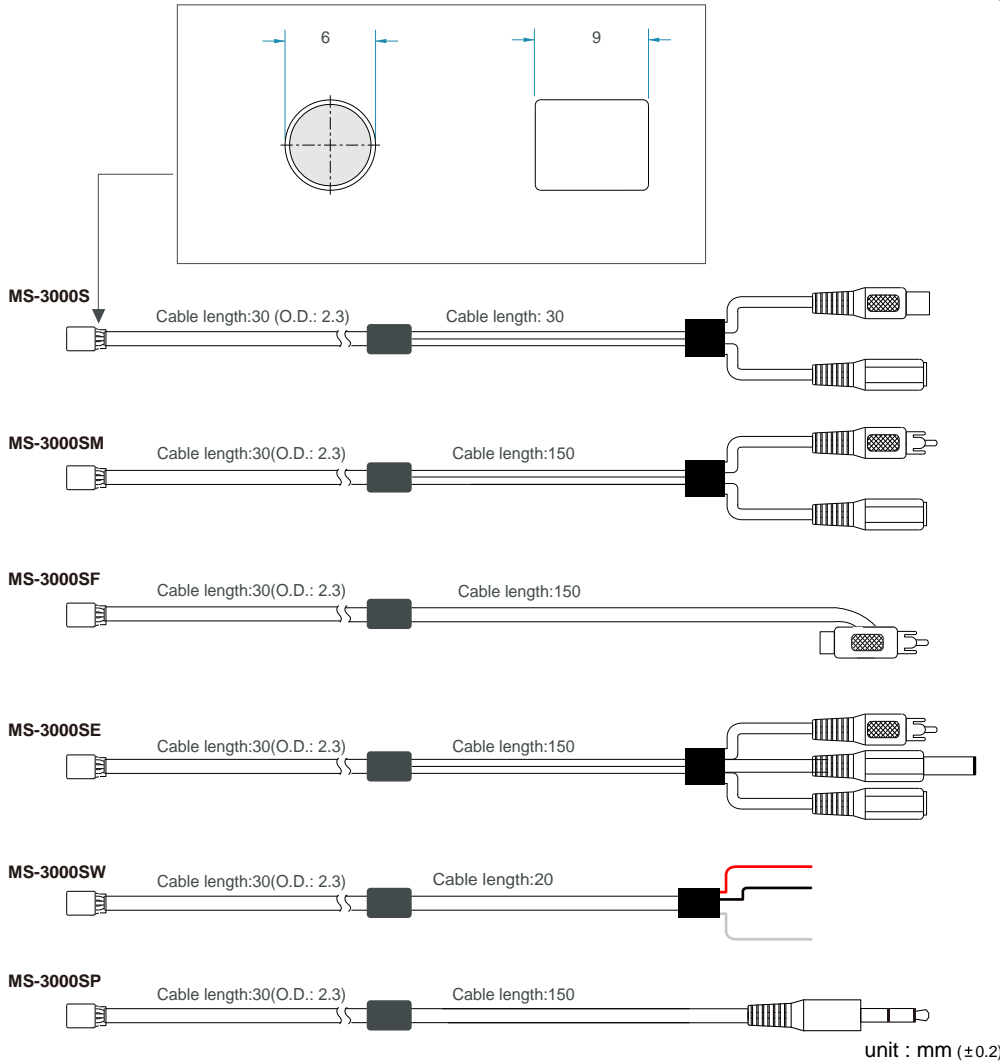

MS-3000S

**Specification**

Model	MS-3000S	MS-3000SF	MS-3000SM	MS-3000SE	MS-3000SW	MS-3000SP
Frequency	20 -16000Hz					
Sensitivity(dB)	-44dB ±3dB(at 1,000HZ)					
Output Impedance(Ω)	600 ohms ±20%(at 1000 HZ)					
S/N Ratio	more than 58dB					
Power Source	DC 5~12V					
Dimension	(D)6 x 9 mm					

**Other information**

**MS-3500**

■ GAIN CONTROL VALUE CHANGEABLE

Frequency: 20 -16000Hz  
S/N Ratio: more than 58dB  
Impedance: 150 ohms ±20%(at 1000 Hz)  
Sensitivity: -44dB ±3dB(at 1,000Hz)  
Dimension : 6X18X4 mm



**MS-6300W**

■ MINI MICROPHONE

Frequency: 20 -16000Hz  
S/N Ratio: more than 58dB  
Impedance: 150 ohms ±20%(at 1000 Hz)  
Power : DC 7~12V  
Dimensions: 6x18x3.5 mm

