

UCD-211



UCD-211M

Feature


- No driver install (USB Video Class)
- A/V CVBS NTSC / PAL input
- Play & Plug with USB Video Class
- Compact size perfect for travel and portable use.

Unit : mm (± 0.5)


Specification

Model	UCD-211-5.0		UCD-211-5.0-N		UCD-211-5.0-P		UCD-211-3.3		UCD-211-3.3-N		UCD-211-3.3-P	
Video input	NTSC, PAL @ 30fps		NTSC @ 30fps		PAL @ 25fps		NTSC, PAL @ 30fps		NTSC @ 30fps		PAL @ 25fps	
UVC output	UVC 1.0		UVC 1.0		UVC 1.0		UVC 1.0		UVC 1.0		UVC 1.0	
	H.264		H.264		H.264		H.264		H.264		H.264	
	MJPEG		MJPEG		MJPEG		MJPEG		MJPEG		MJPEG	
	YUY2		YUY2		YUY2		YUY2		YUY2		YUY2	
Audio output	UAC 1.0											
	PCM, 48kHz, 16bit											
Interface	USB 2.0 /PC											
	4 PIN (female) DC 5V power output						DC 3.3V power output					
OS support	Driver free (USB Video Class) for any OS (windows XP · Vista · win7, Linux any version, MAC OS)											
Storage temperature	-40°C~85°C											
Working temperature	-10°C~60°C											
Power	DC 5V (300mA-max)											
Dimension (mm)	100.6(L) x 30.3(W) x 15(H)											
<ul style="list-style-type: none"> ■ Cross color suppression ■ 3-D deinterlacing ■ Driver free (USB Video Class) for any OS (windows XP · Vista · win7, Linux any version, MAC OS) no ROOT required ! Just connect UVC camera with Android 4.3 OS flat via UHD-220 												

Instruction Drawing & Description

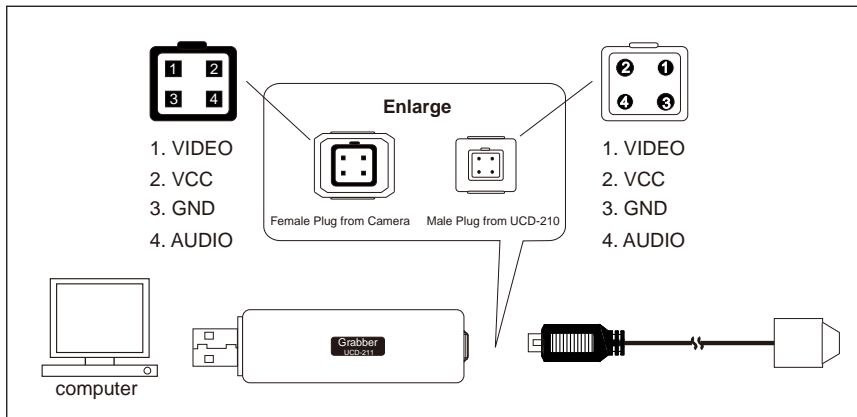

Model	Note
UCD-211-5.0	with plastic case
UCD-211-5.0-N	
UCD-211-5.0-P	
UCD-211-3.3	
UCD-211-3.3-N	
UCD-211-3.3-P	
UCD-211M-5.0	Board type
UCD-211M-5.0-N	
UCD-211M-5.0-P	
UCD-211M-3.3	
UCD-211M-3.3-N	
UCD-211M-3.3-P	

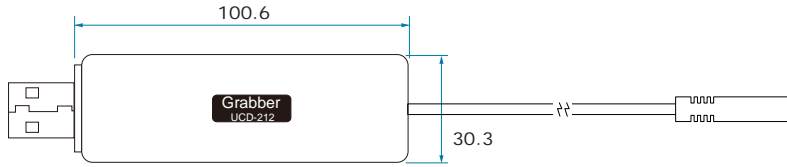

Feature

- No driver install (USB Video Class)
- A/V CVBS NTSC / PAL input
- Play & Plug with USB Video Class
- Compact size perfect for travel and portable use.

Unit : mm (± 0.5)

Specification

Model	UCD-212-3.3		UCD-212-3.3-N		UCD-212-3.3-P	
Video input	NTSC, PAL @ 30fps		NTSC @ 30fps		PAL @ 25fps	
UVC output	UVC 1.0	640 x 480 320 x 240 @ 30fps	UVC 1.0	720 x 480 640 x 480 320 x 240 @ 30fps	UVC 1.0	720 x 576 640 x 480 320 x 240 @ 30fps
	H.264		H.264		H.264	
	MJPG		MJPG		MJPG	
	YUY2		YUY2		YUY2	
Audio output	UAC 1.0					
	PCM, 48kHz, 16bit					
Interface	USB 2.0 /PC					
	DC 3.3V power output					
OS support	Driver free (USB Video Class) for any OS (windows XP \ Vista \ win7, Linux any version, MAC OS)					
Storage temperature	-40°C~85°C					
Working temperature	-10°C~60°C					
Power	DC 5V (300mA-max)					
Dimension (mm)	100.6(L) x 30.3(W) x 15(H)					
	<ul style="list-style-type: none"> ■ Cross color suppression ■ 3-D deinterlacing 					
	<ul style="list-style-type: none"> ■ Driver free (USB Video Class) for any OS (windows XP \ Vista \ win7, Linux any version, MAC OS) no ROOT required ! Just connect UVC camera with Android 4.3 OS flat via UHD-220 					



Instruction Drawing & Description

