


Feature

- Full HD USB camera!
- High sensitivity!
- High performance.
- Full HD 1080p, H.264

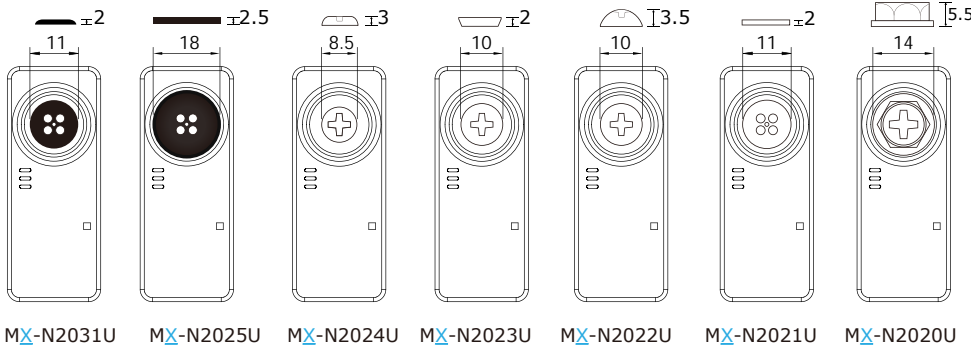

Specification

Model	MM-N20XXU
Max. frame rate	1920x1080/30fps H.264, MJPEG; 5fps YUV 1280x720/30fps H.264, MJPEG; 10fps YUV 640x480/30fps, 640x360/30fps H.264, MJPEG, YUV 320x240/30fps, 320x180/30fps H.264, MJPEG, YUV
pixel size	3 μm x 3 μm
Image sensor	1/2.7" digital cmos camera module
Image area	5856 μm x 3276 μm
Scan mode	progressive
Sensitivity	3300 mV/Lux-sec
Dynamic range	69 dB @ 8x gain
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Interface	USB 2.0 (Compliant with USB Video Class 1.1 standard)
Output format	YUV、MJPEG、H.264
Built-in Lens	6.0mm/F2.0
Operating system	Windows OS(Win7 & Win8) Linux OS(kernel 2.6.27 or later), Android OS
Power source	DC 5V (Micro USB OTG B type)
Power current	350mA(Min.)
Dimension(mm)	22.8 x 57
Audio	Built-in microphone


Slim Size is perfect for wearable and hidden!



Order Information

MODEL	OUTPUT
MD-N20XX	USB 2.0 A type
MM-N20XX	Micro USB OTG B type
MT-N20XX	USB Type-C

Order information

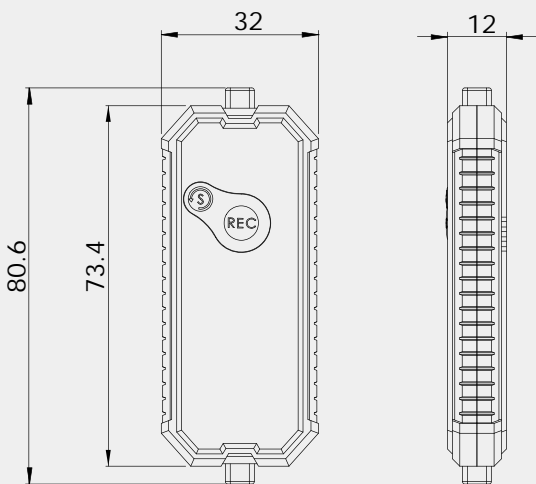

MP-WF580K / MP-WF580KP

Feature

- Support micro SD 128GB
- P2P or IP network connection
- Support H.264 & MJPG video format input
- WIFI Mini DVR
- FTP receiver (file)
- Live streaming preview(http)
- Loop receiver
- Support UVC camera video input
- Support RTC

Portable Size
&
Super Slim



External Memory - Max Support 128GB



UVC camera input
 (3 types Connector-optional)



USB A



Micro USB



Type C

Snapshot/reset

Record



power input
 (power bank/power supply)
 -USB 2.0 (female)
 -Micro USB (female)
 (order in advance)



APP
 Preview



FTP



Http
 Preview



Wi-Fi



IP/ P2P



UVC
 Camera



Loop
 Record



H.264
 MJPG
 video
 Fomat



128GB
 Micro SD



RTC
 Function

