


Digital type

Feature

- Miniature size
- High sensitivity!
- High performance.
- Telescope Hidden camera

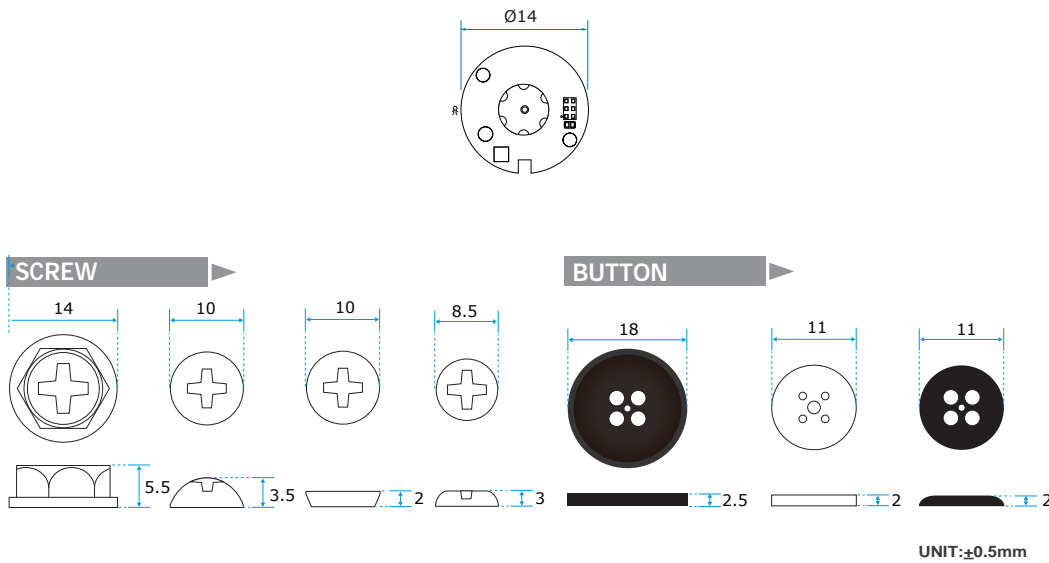

Specification

Model	HS-B112310-3X
Max. frame rate	640x480@ 30fps MJPG/ 30fps YUV
Microphone	Built-in
Pixel size	1.4 μm x 1.4 μm
Image sensor	1/16.1"(crop sensor) Digital CMOS Camera Module
Image area	0.90 x 0.67mm
Scan mode	progressive
Sensitivity	553 mV/(Lux-sec)
Dynamic range	73.3 dB @ 15.5x gain
UVC format	MJPEG, YUY2
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Interface	USB 2.0 (Compliant with USB Video Class 1.1 standard)
Built-in Lens	3.4mm/F2.8
View angle	H= 15° 5'; V= 11° 15'; D= 18° 42'
Operating system	MAC OS, Windows10, Windows8, Windows7, Windows XP, Linux, Andriod
Power source	DC 5V (USB)
Power current	160mA
Dimension(mm)	Ø14

order information

Model	Output
HS-B112310	USB 2.0 A type
HSM-B112310	Micro USB OTG B type
HST-B112310	USB type C

