

UNIT:±0.5mm

Feature


- Miniature size with dimmer function!
- Driver free (USB Video Class) for any OS (windows XP、Vista、win7, Linux any version, MAC OS、Andriod phone)

Specification

Features:	<ul style="list-style-type: none"> • Connects to Windows XP machines USB 2.0 port • TCP Video MJPEG stream 1280 x 720 /YUV 10fps/ MJPEG 30fps/H.264 24fps 640 x 480 /30 fps; 640 x 360 /30 fps; 320 x 240 /30 fps; 320 x 180 /30 fps • Driver free (USB Video Class) for any OS (windows XP Linux any version, MAC OS)
pixel size	3 umx3 um
Image sensor	1/4" WXGA HD 720P Camera
Image area	3888 um x 2430 um
S/N Ratio	39 dB
Scan mode	progressive
Sensitivity	3300mV/(Lux)
Dark Current	20 mV/Sec
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Built-in Lens	3.4mm /F2.8
LED	white light LED x 10
Power source	DC 5V
Power current	150 mA
Dimension(mm)	Ø10 x 36mm



MX-V4110L

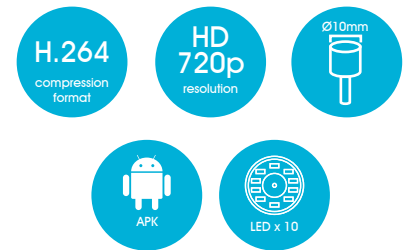

order information

MODEL	Output	Compatible with UHS-DC02E	Available Software	Note
MD-VB4110L	USB 2.0 A type	YES		MD-VB4110L B: camera module
MD-V4110				
MD-V4110L				
MM-V4110	Micro USB OTG B type	N/A		
MM-V4110L				
MT-V4110	USB type C			
MT-V4110L				

