

Unit : mm (± 0.5)



MST-WF16N


Feature

- Wireless Display
- Smart TV (Mini PC)
- Full HD 1080P Video Out
- Android 4.4 Jellybean system

Specification

Resolution	1280x720, 640x480 @30fps
Transmission distance	5~30m
Wireless frequency	3.412G~2.462G
Image format	MJPEG
Video format	Avi.
System requirement	IOS/Android/Windows
Power output	DC5V(micro USB for camera)
Battery Capacity	850mAh(included)
Power Supply	Built in battery(DC5V-micro USB for charging)
Dimension(mm)	62(L)x35(W)x17(H)

Overview

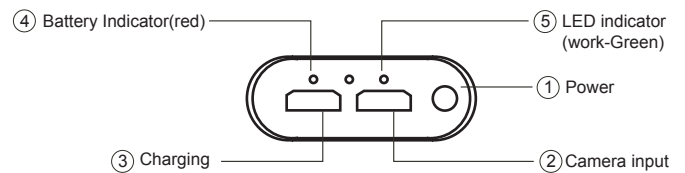

Used on phone

1. Download APP or APK:
(ios)Serach the App Store for "Sea_Otter" in the App Store QR code,and download it.
- (android)Serach the google play for "WiFi View" in the App Store QR code,and download it.



3. Install wifi view app,then the icon will show on your android phone. the icon will show on your iphone
4. Turn on the phone wifi, after 15 seconds,and find "ZCF" of the wifi name.Connect it,password is 12345678, then ⑤ green led flashes slowly. It indicate that the WiFi has connected successfully.
5. Press wifi view app, and then camera connect to smartphone. ⑤ LED flashes fastly, you can take photo and viedo.

Other information

Image									
Model	MM-V1001L	MM-V1003L	MM-V20904L	MM-V21106L	MM-V31105L	MM-V4110L	MM-V5015L	MM-N40XX	MM-N20XXE
Dimension	Ø2.5mm	Ø3.8mm	Ø4.2mm	Ø6mm	Ø5.4mm	Ø10mm	Ø15mm	10.3x40.7mm	22.8x57.4mm
Resolution	400x400 @30fps	400 x 400	1280x720 @ 30fps MJPG @ 10fps YUV	1280x720 @ 30fps MJPG @ 10fps YUV	1920x1080 @ 30fps MJPG @ 3fps YUV	1920x1080 @ 24fps H.264 @ 30fps MJPG @ 10fps YUV	2592 x 1944 @15 fps MJPG	1920x1080 @ 24fps H.264 @ 30fps MJPG @ 10fps YUV	1920x1080 @ 30fps H.264 @ 30fps MJPG @ 10fps YUV
Image sensor	1/18"	1/10"	1/9"	1/9"	1/6"	1/4"	1/4"	1/4"	1/2.7"
LED	White LED x 3	White LED x 4	White LED x 6	White LED x 6	White LED x 6	White LED x 10	White LED x 10	N/A	N/A
UVC format	YUV MJPEG	YUV MJPEG H.264	YUV MJPEG	YUV MJPEG	YUV MJPEG	YUV MJPEG H.264	MJPEG	YUV MJPEG H.264	YUV MJPEG H.264
Type	Tube	Tube	Tube	Tube	Tube	Tube	Tube	Hidden	Hidden
Note	Datasheet	Datasheet	Datasheet	Datasheet	Datasheet	Datasheet	Datasheet	Datasheet	Datasheet