


Feature

- 4 White SMD LED Lighting
- Multiple applications
- High performance.

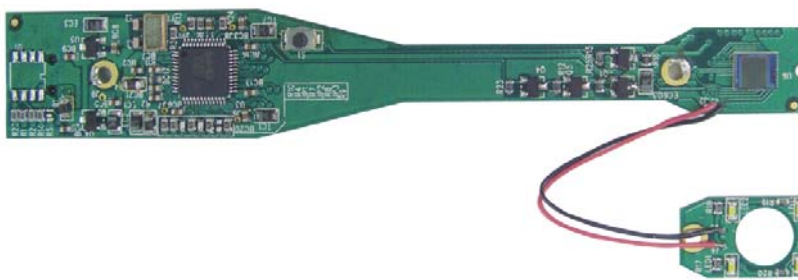

Specification

Model	MD-MB4103
Image Transfer Rate	SXGA 15fps ; VGA 30fps ; QVGA, QQVGA, CIF 30fps ; QCIF, QQCIF 30fps
Image sensor	1/4" CMOS color
Built-Lens	Specify when ordering
Video Format	(8-bit) YUV/YCbCr 4:2:2 GRB 4:2:2 Raw RGB Data
LED	4 White SMD LED Lighting (IR LED optional)
Power source	DC 5V
Power current	80mA
OS support	Windows 2000, XP, windows 7 or windows 10
Dimension (mm)	18 x 110



3.4mm / F 7.0 (M5.5)

Model: MD-MB4103-3S



3.4mm / F 5.7 (M6)

Model: MD-MB4103-3X6

Other lens

Image		
Model	MD-MB4103-3Z	MD-MB4103-3D
Lens	3.4mm/F7.0(M5.5)	3.9mm/F2.8(M7)