


Unit : mm (± 0.5)

Tube Type

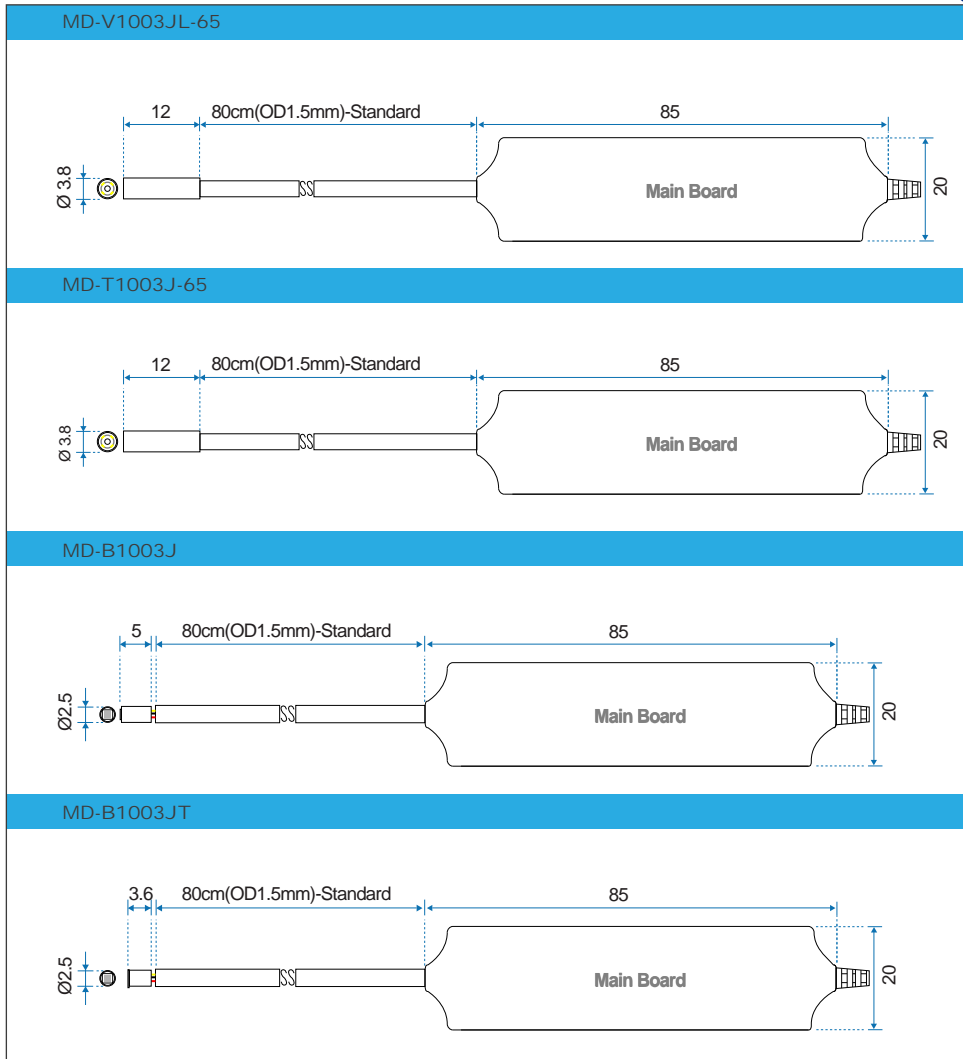

Feature


- Compact size.
- 2.5 mm Only(MO-B1003) !!
- High Performance.
- Outstanding Quality!
- Competitive Price!



▲ MD-V1003JL-65



▲ MD-T1003J-60

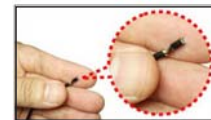

▲ MD-B1003J



▲ MD-B1003JT

Specification

Model	MD-V1003JL-65	MD-T1003J-65	MD-B1003J	MD-B1003JT
LED Light	white light LED x4	W/O LED	W/O LED	W/O LED
Number of effective pixels	400 x 200			
Image sensor	1/10" CCIQ II Color Camera			
Resolution(TV Lines)	300 TV Lines			
Minimum illumination	2Lux /F3.4			
Frame rate	60 fps			
OS Support	vista, window XP, windows 7, windows 8 , windows 10			
Storage temperature	-30 to 60 Degree C			
Working temperature	-10 to 45 Degree C			
Built-in Lens	1.49mm /F5.0		W/O LENS	
Connector	USB 2.0 A type			
Power source	Camera : DC 5 V			
Power current	200 mA-max			
Dimension (mm)	Senear board: 3.8 x 12 (mm) + cable: 800(mm) + main board: 20 x 85 (mm)	Senear board: 3.8 x 12 (mm) + cable: 800(mm) + main board: 20 x 85 (mm)	Senear board: 2.5 x 5 (mm) + cable: 800(mm) + main board: 20 x 85 (mm)	Senear board: 2.5 x 3.6 (mm) + cable: 800(mm) + main board: 20 x 85 (mm)