
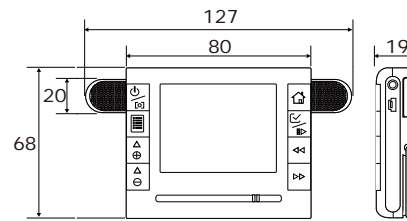


sunglasses

DVR

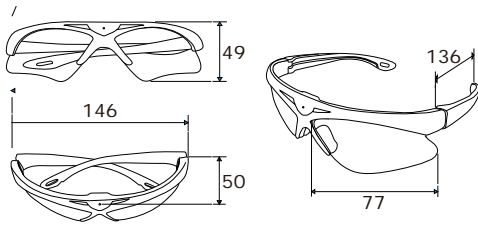

Feature

- High Sensitivity!
- High Performance.
- 1/3" CCIQ III Color
- 976 x 496 Pixel
- Compact size

Specification

unit : mm (±0.2)

Model: MP-HS18588B	
Video system	NTSC / PAL
Number of effective pixels	976 (H) x 496(V) (NTSC & PAL)
Effective Image Area	4.88 mm x 3.67 mm (Diagonal: 6.1mm)
Pixel Size	5.00 um x 7.40 um
Image sensor	1/3" Color CCIQ III 960H Camera
Resolution(TV Lines)	710TV Line over (NTSC) , 740TV Line over (PAL)
S/N Ratio	46.4 dB
Dynamic range	63.5 [dB]
Sensor scan mode	Interlaced 60 fields
Minimum illumination	0.05Lux at F1.2 20IRE
Shutter Speed	1/60~1/200,000 (NTSC) , 1/50~1/170,000 (PAL)
Sensitivity	11.4 [V/Lux.sec]
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Built-in Lens	3.9mm/F3.9
Power	DC 5-12V
UTC control function	with UTC control function
DVR: MP-455E	
Display	2.5" LTPS TFT LCD 508x240(230K)
External Memory	SDHC /SD card slot (support up to 32GB) , Built-in flash memory 128 MB
Interface	2 in 1 MiniUSB (USB2.0 / Power in) ; 4 in 1 earphone jack (Video out / earphone jack / external microphone / AV in)
Video out / Video in	TV OUT (NTSC / PAL) / AV IN (NTSC / PAL)
Function	Snapshot(640 x 480-jpg) Timebar Scheduled recording function (12 event) Special Power save button (monitor sleep mode)
Extend interface	Extend DC power 9V out for camera and AV in
AV recorder resolution	640 x 480 (VGA) / max 30 fps
AV audio quality	2 modes : radio quality (16KHz) / CD quality (48KHz)
AV recorder quality	MPEG4 : best fine normal basic economy
Voice recorder	2 modes: radio quality (16KHz)/CD quality (48KHz)
Format support	JPEG ASF WAV MP3 WMA
Language support	12 languages: English, German, French, Spanish, Italian, Portuguese , Japanese, simple Chinese, tradition Chinese, Korean, Polish, Turkey
Battery	Rechargeable LI-ION battery(3.7 V /920mA , compatible with NP60 type battery)
Adapter	5V DC adapter (USB port) / USB cable
Weight(g)	95g (with battery)
Size	18 x 68 x 81 (L x W x H) mm



MP-HS18588U



MP-HS28588C-4T



MP-HS18588B-4T



MP-HS18588C-4T

Other information

Model	Glasses Lens style
MP-HS X 8588C-4T	transparent type
MP-HS X 8588B-4T	black tint type
MP-HS X 8588U-4T	UV protection
note	
MP-HS X 8588C-4T	Glasses frame style 1: Black 2: Blue