

Feature

- High sensitivity!
- High performance.
- Full HD image pixel
- Camera parameter adjustable



Unit : mm (± 0.5)

Specification


Model	TM-P560	TM-P566
Earphone color	black	white
Max. frame rate	1920x1080 @ 15~30fps MJPEG 1280x720 960x540 848x480 640x480 640x360 424x240 320x240 320x180 176x144 160x120	
Pixel size	1.4 x 1.4 μm	
Image sensor	1/6" Digital CMOS Camera Module	
Image area	2.7288x1.5498mm	
Scan mode	progressive	
Sensitivity	553 mV/(Lux·sec)	
Dynamic range	73.3 dB @ 15.5x gain	
UVC format	MJPEG	
Storage temperature	-30 to 60 Degree C	
Working temperature	-10 to 45 Degree C	
Interface	USB 2.0 (Compliant with USB Video Class 1.1 standard)	
Built-in Lens	1.83mm/F2.0(77°)	
View angle	H= 70°; V= 42° 7'; D= 77° 3'	
LED	N/A	
Power source	DC 5V (Micro USB)	
Power current	160mA	
Operating system	Windows XP, windows Vista, window 7, windows 8, windows 10, Linux, MAC OSX	
Microphone	Built-in	




▲ TM-P560



▲ TM-P566

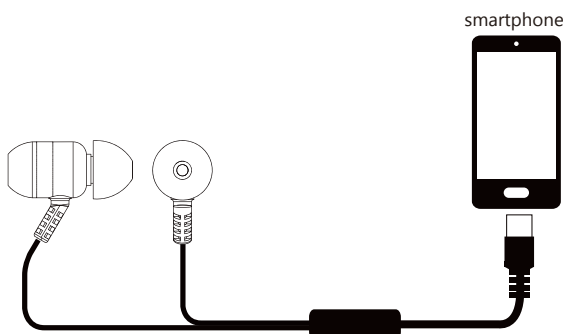

APP

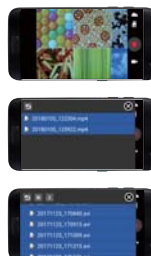

Model: MP-WF580-MM

