


**Feature**

- High performance and outstanding quality.
- Low light Camera
- High sensitivity!
- HD 720p resolution.
- HDR Camera.

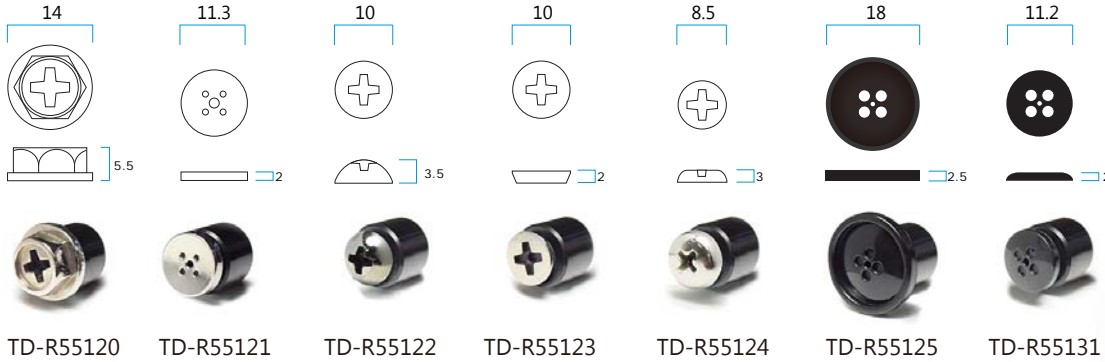

**Specification**

Model	TD-R551xx -62
Pixel size	3.75 x 3.75 μm
Active image size	4.8mm(H) x 2.7mm(V)
Resolution	1280 x 720 @ 30fps MJPG
Image sensor	1/3" CMOS color
Sensor scan mode	progressive
Video format	MJPG
Sensitivity	6488 mV/lux-sec
Max SNR	37.2 db
Max dynamic range	70.4 db
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Built-in lens	4.2mm/F2.4
Power source	DC 5V
Power current	130mA
OS support	Window 7, Windows 8, windows 10, Android
Microphone	Built-in

**Model NO.**

**TD-R55131-62**

① ② ③ ④

① CONNECTOR	② TYPE	③ COVER TYPE	④ LENS
<b>TD</b> USB 2.0 A type <b>TM</b> Micro USB OTG B type <b>TT</b> USB type-C	<b>R</b> with case	<b>55120</b> silver screw (Ø14mm) <b>55121</b> silver button (Ø11mm) <b>55122</b> silver screw (Ø10mm) <b>55123</b> silver screw (Ø10mm) <b>55124</b> silver screw (Ø8.5mm) <b>55125</b> screw (Ø18mm) <b>55131</b> screw (Ø11mm)	<b>62</b> 4.2mm/F2.4 (62°)