


unit: ±0.5mm

Feature

- Miniature size
- High sensitivity!
- High performance.
- Full HD image pixel

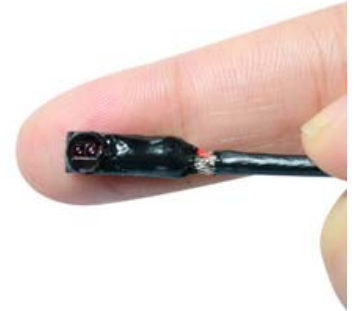

Specification

Model	TD-DL31105-11930
Camera type	left side view
Snapshot & Freeze Function	Specify when ordering
Camera parameter setting on smartphone	support
Compatibility with wifi DVR (MP-WF580K)	support
Dimension(mm)	Ø7.3
Max. frame rate	1920 x 1080 @ 15~30fps MJPEG 1280 x 720 960 x 540 848 x 480 640 x 480; 640 x 360 424 x 240 320 x 240; 320 x 180 176 x 144; 160 x 120
Pixel size	1.4 μm x 1.4 μm
Image sensor	1/6" Digital CMOS Camera Module
Image area	2.7288 x 1.5498mm
Scan mode	progressive
Sensitivity	553 mV/(Lux-sec)
Dynamic range	73.3 dB @ 15.5x gain
UVC format	MJPEG / YUV
Storage temperature	-30 to 60 Degree C
Working temperature	-10 to 45 Degree C
Interface	USB 2.0 (Compliant with USB Video Class 1.1 standard)
Built-in Lens	1.19mm/F3.0(dual lens)
LED	N/A
Power source	DC 5V (USB)
Power current	160mA
Operating system	Windows XP, windows Vista, window 7, windows 8, windows 10, Linux, MAC OSX