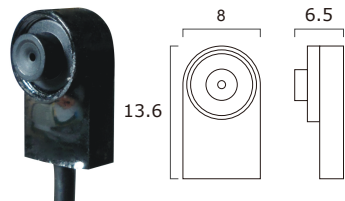
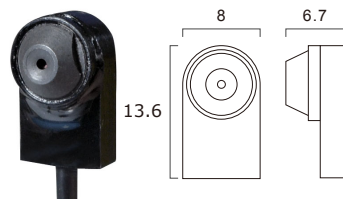


S5508U-3W


2.8 mm / F 3.9 (M 7)


S5508U-3TC

3.5 mm / F 3.5 (M 7 x P 0.5)


S5508U-3M


3.4 mm / F 2.8 (M 6 x P 0.35)

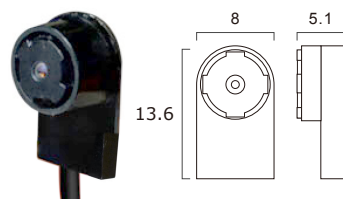

Unit : ± 0.5 mm

VS5508UL-3M

3.4 mm / F 2.8 (M 6 x P 0.35)

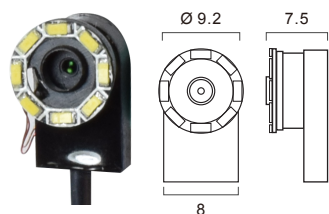
Specification

Model No.	S5508U	S5708U
Display	Color	B/W
Pixel Size (μm)	6 x 6	
Image Area (mm)	3.8 (H) x 2.9 (V) x 4.86 (D)	
Video System	NTSC / PAL	EIA / CCIR
Effective Pixels	648 x 488	
Image Sensor	1/4" CCIQ III Camera	
Resolution (TV Lines)	480	550
S/N Ratio	47 dB	
Dynamic Range	63.3 dB	
Scan Mode	Progressive Scan	
Minimum illumination	0.02 LUX / F 1.2	0.006 Lux / F 1.2
Transfer Rate	60 field / sec (NTSC / EIA) 50 field / sec (PAL / CCIR)	
Sensitivity	8.2 [V/Lux.sec]	
Horizontal Sync Frequency	15.734 kHz (NTSC / EIA) 15.625 kHz (PAL / CCIR)	
Vertical Sync Frequency	60 Hz (NTSC / EIA) 50 Hz (PAL / CCIR)	
Camera Consumption	0.45	
Video Output	1Vp-p , 75 ohm composite	
Storage Temperature	-30 to 60 Degree C	
Working Temperature	-10 to 45 Degree C	
Power Source	DC 5~12 V	
Power Current	100 mA (Max.)	

MO-S5508ULA-3M

SERIES	CONNECTOR	CAMERA BODY	DISPLAY	LED	Microphone	LENS
M Basic	CVBS Signal ○ RCA Female / DC Plug	Up View S Forming Type VS Forming Type + Dimmer	Board Type 5508U Color 5708U B/W * U Up view	L White LED	A Build-In Microphone N/A None	3W 2.8 mm / F 3.9 (80°) 3E 3.0 mm / F 2.4 (77°) 3M 3.4 mm / F 2.8 (70°) 3S 3.4 mm / F 7.0 (70°) 3TC 3.5 mm / F 3.5 (68°)

Feature

- Compact size.
- Hi Resolution up to 480 TV Lines.
- High Performance.
- Outstanding Quality!
- Competitive Price!