


Feature

- 7-inch full view (1024 x 600pix) HD screen.
- Built-in 7000mAh high capacity Li-battery.
- 4x zoom monitoring
- HD TVI, CVI, AHD, CVBS 4 in 1 video balun.
- 800 meters HD TVI 1080P 75-5 signal reliable transmission.
- Compressed video and audio are synchronous.
- Support H.264 encoding.
- Up to 5MP resolution recording.
- Support Loop recording and No-Loop recording.
- Support for composite video output.
- Support earphone monitoring.
- Working voltage: 5~12V.
- Supports up to 128GB TF card.
- Supports multi-language.
- Power-saving mode :automatic off-screen.
- System upgrade: supports system upgrade.
- Support 12 voltage power output for camera.

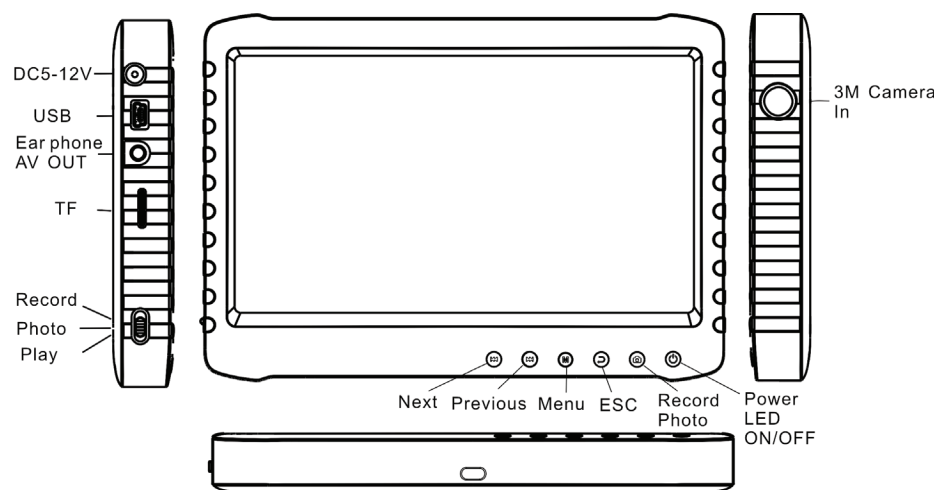

Specification

Model No.	MP-906	MP-908
Sunshade	N/A	With Sunshade
Display	Resolution	1024 x 600 Pixel
	View Angle	Full view 170 °
Video	Brightness	350 cd / m ²
	Input	HD TV, CVI, AHD, CVBS
	Transmitting Range	800 meters for TVI 1080P signal
	Delay Time	<0.1s
	Power Output	12V / 300 mA
	LED Control Output	LED On / Off
	Storage Pixels (16:9)	1920 x 1080
	Compress	H.264
	Video Storage Format	AVI
Audio	Frequency Range	20HZ-20KHz AAC
	Compression Format	AAC
Photo	Storage Format	JPG 5.0 MP (2560 x 1920)
Storage	External Storage	TF card 2-128GB (Optional)
	128gb Recording Time	18~60 hours
Operating System	PC	Windows & MAC OS
	Port	USB 2.0
Power	Working Voltage	DC 5~12V
	Working Current	2A
Battery	Built-in Li Battery	7000mAh
	Working Time	≥ 5 hours
Dimension (mm)		175 (W) x 120 (L) x 20 (H)
Weight (g)		215

