


Feature

- 3.5" TFT Display
- Support 32GB x 2 Micro SD Card
- IR Remote Control
- With 5 Megapixel Camera




Magnetic Camera Cap
four sides + top all have magnetic




MP-700
(5.2 mm / F 2.8)

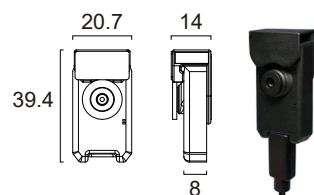

MP-710
(3.0 mm / F 2.0)

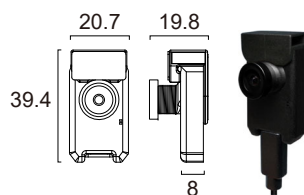

MP-711
(3.0 mm / F 2.0)

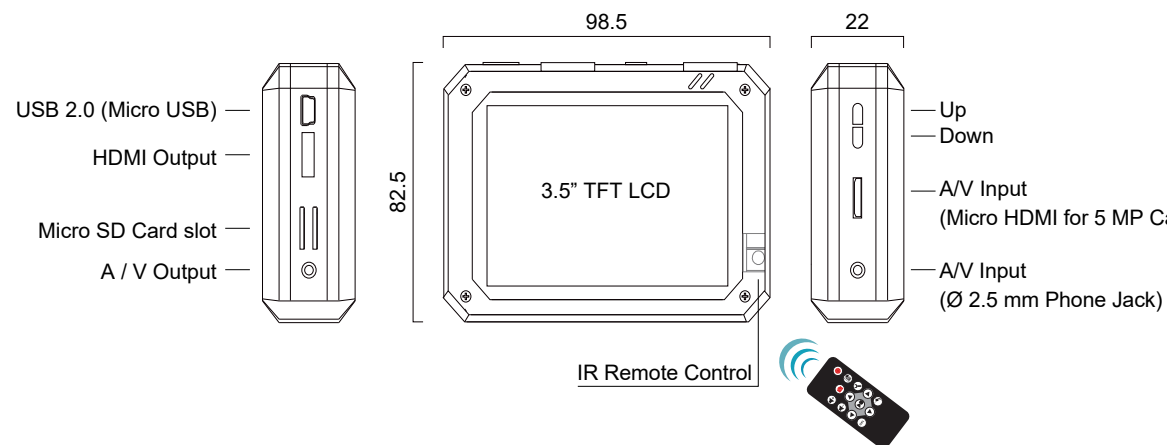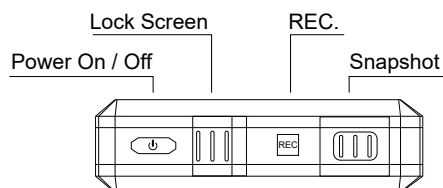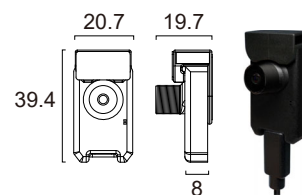

Specification

Model No.		MP-700	MP-710	MP-711
Lens		5.2 mm / F 2.8	3.0 mm / F 2.0	3.0 mm / F 2.0
Camera	Resolution	5 Megapixel		
	Image Sensor	1/2.5" CMOS		
	Pixel Size (µm)	2.2 x 2.2		
Video	File Format	MOV (H.264)		
	Record Quality	HDMI: 1080p / 720p / 848 x 480 CVBS: 720 x 576		
	RTC Stamp	Support		
	Record Mode	Normal / Loop recording / Motion Detection		
Audio	Output	48 KHz		
	Speaker	Support		
Photo	File Format	JPG 5 MP		
I/O Interface	A/V Input	Ø 2.5 mm Phone Jack for CVBS Camera (DC 5V / 250 mA) Micro HDMI for 5 MP Camera		
	A/V Output	Ø 3.5 mm Phone Jack HDMI Line Out		
	IR Remote Control	Support		
Storage	SD Card Slot	Micro SD card 32 GB x 2		
Battery	Built-in Li Battery	Li-ion NP 120 (2000 mAh)		
	Status Indicator	(100% 2 hr) Full (50% 1 hr) Middle (10% min.) Blinking for 30 sec. (5%) Red LED on and Power off after 1 min.		
Power Input		USB 2.0 (Micro USB) DC 5V		
Dimension (mm)		82.5 (W) x 98.5 (L) x 22 (H)		
Display		3.5" TFT LCD		



MP-700