



Feature

- 2.0" TFT Display
- Support 32GB x 2 Micro SD Card
- GPS Function
- With 5 Megapixel Camera

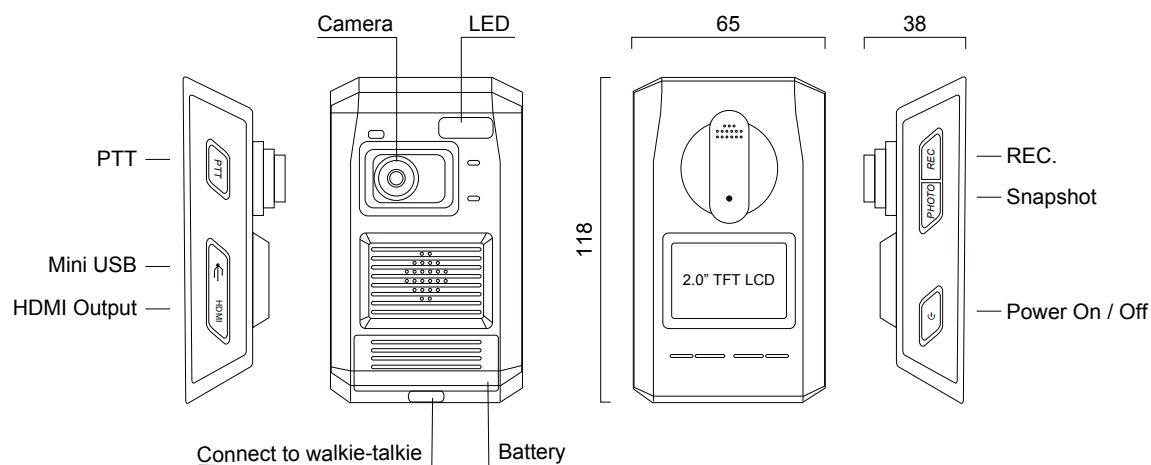

Specification

Model No.	MP-800	MP-810
Intelligent IR LED	IR 850 nm & IR 940 nm	White & IR 940 nm
Camera	Resolution	5 Megapixel
	Image Sensor	1/2.5" CMOS
	Pixel Size (μm)	2.2 x 2.2
Video	File Format	MOV (H.264)
	Record Quality	HDMI: 1080p / 720p / 848 x 480 CVBS: 720 x 576
	RTC Stamp	Support (be set by GPS)
	Record Mode	Normal / Loop recording
Audio	Output	48 KHz
	Speaker	Support
Photo	File Format	JPG 5 MP
Storage	SD Card Slot	Micro SD card 32 GB x 2
A/V Output	HDMI Line Out	
Built-in Li Battery	Li-ion NP 120 (2000 mAh)	
Power Input	USB 2.0 (Micro USB) DC 5V	
Dimension (mm)	65 (W) x 118 (L) x 38 (H)	
Display	2.0" TFT LCD	
GPS Function	GPS tracker to record image locations on a google map	

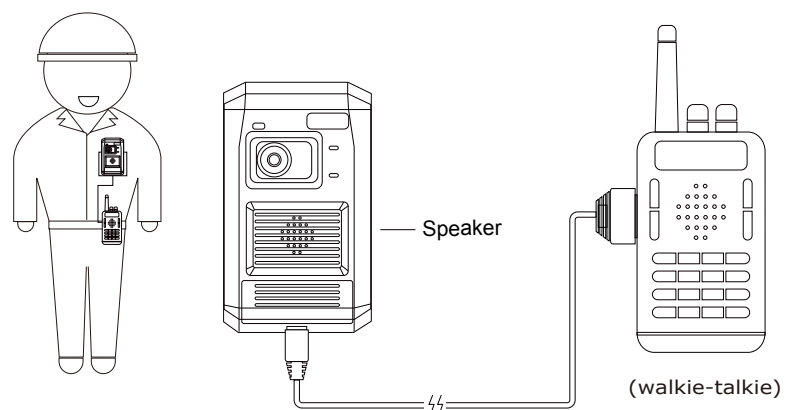

MP-800

MP-810