


Feature

- Ideal for covert applications.
- Disguised easily in the shirt and can be used with a camcorder or mini-DVR.
- Easy to conceal, easy to operate, and easily fits into any environment.
- Use as a Body-Worn or hidden camera.

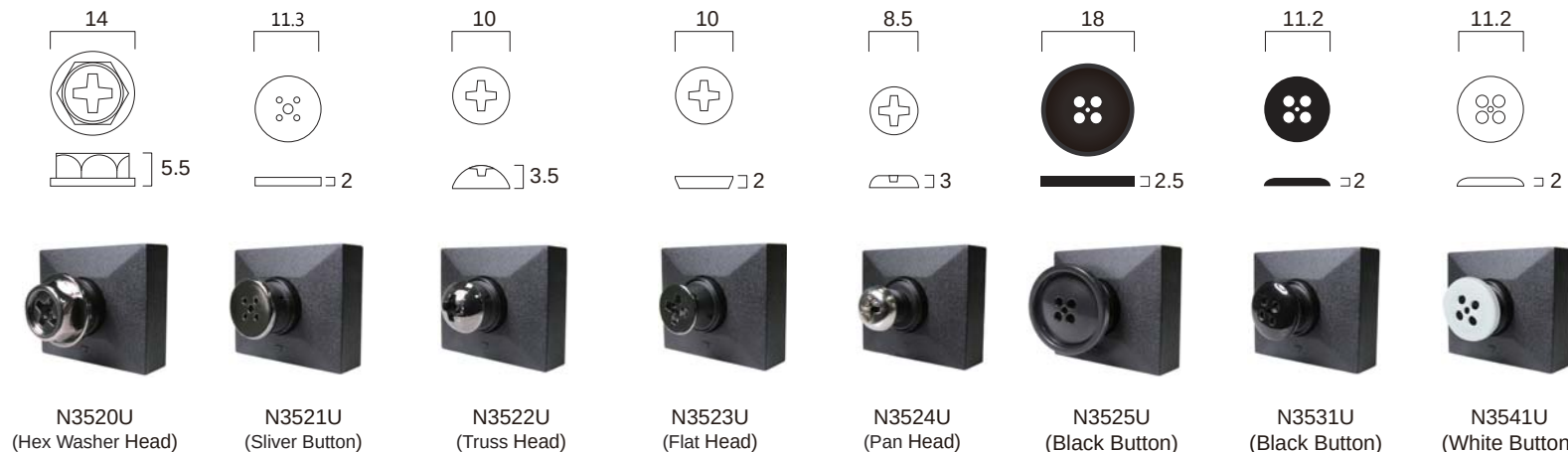

Specification

Model No.	N35	N55	N96
Pixel Size (μm)	5.55 x 5.55	6.0 x 6.0	5.0 x 6.2
Image Area (mm)	3.60 x 2.71	3.80 x 2.90	4.88 x 3.67
Image Circle (mm)	Ø 4.50	Ø 4.86	Ø 6.10
Sensitivity (V/Lux.sec)	3.53	8.2	10.9
Dynamic Range (dB)	68.2	63.3	63.5
S/N Ratio (dB)	45.6	47	46.4
Image Sensor (CMOS Color)	1/4"	1/3.7"	1/3"
Pixel	648 x 488		960 x 576
Video Format	NTSC / PAL		
Scan Mode	Progressive		
Shutter	Rolling		
Horizontal Sync Frequency	15.734 kHz (NTSC) 15.625 kHz (PAL)		
Vertical Sync Frequency	60 Hz (NTSC) 50 Hz (PAL)		
Frame Rate	60 fields / sec. (NTSC) 50 fields / sec. (PAL)		
Gamma Consumption	0.45		
Video Output	1Vp-p , 75 ohms Composite		
Focus Distance (mm)	Infinity		
Storage Temperature	-30 to 60 Degree C		
Working Temperature	-10 to 45 Degree C		
Power Supply	DC 5~12 V		
Power Current	80 mA		

MO-N3520UA-4F

SERIES	CONNECTOR	CAMERA BODY	DISPLAY			
M Basic	<u>CVBS Signal</u>		<u>Color</u>	<u>B/W</u>	<u>Image Circle</u>	
	O Mini 4 pin		35	37	Ø 4.50 mm	
	J Phone Plug		55	57	Ø 4.86 mm	
	Q Waterproof		96	99	Ø 6.10 mm	
F RCA / DC		N Plastic Case				
COVER			MICROPHONE		LENS	
20U Hex Washer Ø 14			A External	<u>Code</u>	<u>Specification</u>	<u>View Angle</u>
21U Sliver Button Ø 11			N/A None	4F	4.3 mm / F 2.0	56° 70°
22U Truss Head Ø 10						
23U Flat Head Ø 10						
24U Pan Head Ø 10						
25U Black Button Ø 18						
31U Black Button Ø 11						
41U White Button Ø 11						
*U Up View				*Different image circle may have different view angle.		
Connector Information						
				NOTE: G GND A AUDIO P DC POWER V VIDEO		
Mini 4 Pin	Phone Jack	M8 Waterproof	RCA / DC			

Other Information

Lens Cover Only. (Exclude Lens)
A sewing kit includes
3 White and 3 Black Thread Needles.
4 Types of Buttons + 4 Types of Screws with thread.
6 Buttons without thread. (1 for each type)
*All lens covers come with M7 x P 0.5 thread.



▲ LPH-100



Cover can be changed