


Feature

- High Performance.
- Outstanding Quality.
- UVC Signal Output.
- Low Light Camera.
- HD 720p Resolution.
- HDR Side View Camera.

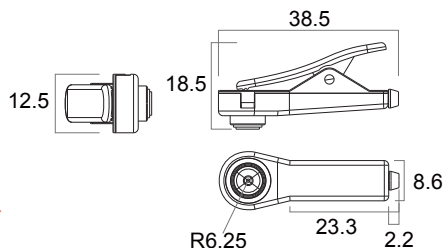


Specification

Model No.	NL551
Pixel Size (μm)	3.75 x 3.75
Image Area (mm)	4.8 x 2.7
Resolution	1280 x 720 @ 30 fps MJPEG
Image Sensor	1/3" CMOS color
Sensor Scan Mode	Progressive
Video Format	MJPEG
Sensitivity	6488 mV / Lux-sec
S/N Ratio	37.2 db
Dynamic Range	70.4 db
Storage Temperature	-30 to 60 Degree C
Working Temperature	-10 to 45 Degree C
Lens	4.2 mm / F 2.4
Power Source	DC 5V
Power Current	130 mA
Operating System	Windows Xp, Windows Vista, Window 7 Windows 8, Windows 10, Linux, Mac OSX
Audio Output (Optional)	Built-In (3.25 MHz, S/N more than 62 dB)

NL55120A
Hex Washer Head Ø 14



NL55121A
Sliver Button Ø 11

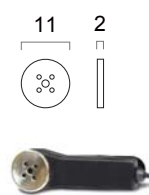


NL55122A
Truss Head Ø 11



NL55123A
Flat Head Ø 11



NL55124A
Pan Head Ø 11

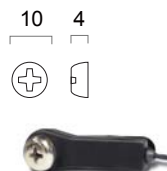

NL55125A
Black Button Ø 18



NL55131A
Black Button Ø 11



NL55141A
Black Button Ø 11



TD-NL55120A-62

SERIES	CONNECTOR	CAMERA TYPE	DISPLAY	COVER	MICROPHONE	LENS
FT Advance T Advance *F Snapshot and Freeze Frame	UVC Signal D USB 2.0 Type A USB 2.0 Micro M Type B (OTG) T USB 2.0 Type C I USB 2.0 Mini Type B Connector Information  USB Type A  USB Micro Type B  USB Type C  USB Mini Type B	Side View NL Plastic Case	551 Color	20 Hex Washer Head Ø 14 21 Sliver Button Ø 11 22 Truss Head Ø 10 23 Flat Head Ø 10 24 Pan Head Ø 10 25 Black Button Ø 18 31 Black Button Ø 11 41 White Button Ø 11	A Built-in N/A None	62 4.4 mm / F 2.4 (59°)