





Mini Spy Camera



Lens Cover KIT For User Change Easily!

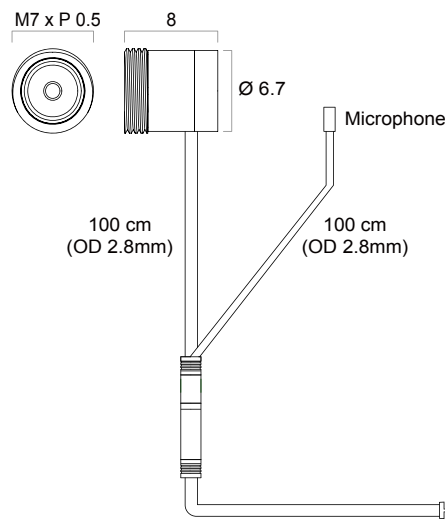

Unit : ± 0.5 mm

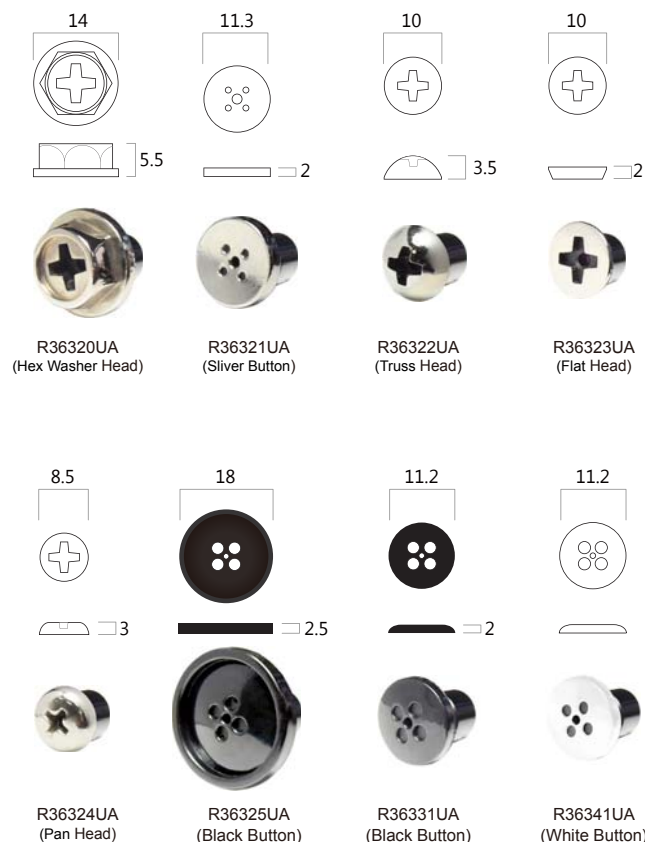

Feature

- Ideal for covert applications.
- Disguised easily in the shirt and can be used with a camcorder or mini-DVR.
- Easy to conceal, easy to operate, and easily fits into any environment.
- Use as a Body-Worn or hidden camera.
- Easily view pictures/videos by connecting it to your devices.
(Smartphones, laptops, tablets, etc.)

Specification

Model No.	R363xxUA
Pixel Size (μm)	1.12 x 1.12
Active Image Size (mm)	2.9 x 2.18
Resolution	2592 x 1944 @ 24 fps MJPEG / YUV
Image Sensor	1/5" CMOS color
Sensor Scan Mode	Progressive
Video Format	MJPEG / YUV
Sensitivity	3.6V / Lux-sec
Max SNR	37 dB
Max Dynamic Range	64.7 dB
Storage Temperature	-30 to 60 Degree C
Working Temperature	-10 to 45 Degree C
Lens	3.0 mm / F 2.4
View Angle	H=51°36'; V=39°56'; D=62°21'
Power Source	DC 5V
Power Current	220 mA
OS Support	Windows 10, Android
Microphone	External (Cable Length 100 cm)

FYD-R36325UA-62

SERIES	CONNECTOR	CAMERA TYPE	DISPLAY	MICROPHONE	LENS
USB 3.0 Interface FY Low Temperature Y Low Temperature *F Snapshot and Freeze Frame	UVC signal D USB Type A M USB Micro Type B (OTG) T USB Type C I USB Mini Type B	R363 Color	20U Screw Cross Ø 14 21U Button Silver Ø 11 22U Screw Curve Ø 10 23U Screw Flat Ø 10 24U Screw Curve Ø 8.5 25U Button Black Ø 18 31U Button Black Ø 11 *U Up View	A External N/A None	62 3.0 mm / F 2.4 (62°)

Connector Information

