


Feature

- UTC Function
- High Performance
- Outstanding Quality!

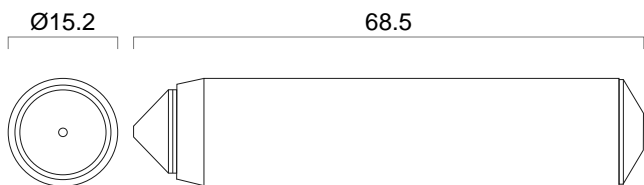

Unit: ±0.5mm

MF-5058-4V

SERIES	CONNECTOR	DISPLAY	LENS
M Basic	CVBS Signal		
	O Mini 4 pin	5058 Color	4V 4.3 mm / F 2.0
	J Phone Plug	7058 B/W	16 16 mm / F 2.0
	Q M8 Waterproof		
	F RCA / DC		

Specification (Camera)

Model No.	5058-4V
Pixel Size (um)	5.6 x 5.6
Effective Image Area (mm)	3.99 x 3.09
Video System	NTSC / PAL
Effective Pixels	712 x 552
Image Sensor	1/4" CMOS Color Camera
S/N Ratio	44.8 dB
Dynamic Range	75 dB
Sensor Scan Mode	Interlace
Image Transfer Rate	60 field/sec (NTSC); 50 field/sec (PAL)
Sensitivity	16 [V/Lux.sec]
Horizontal Sync Frequency	NTSC - 15.734kHz; PAL - 15.625kHz
Vertical Sync Frequency	NTSC - 60Hz ; PAL - 50Hz
Camera Consumption	0.45
Video Output	1Vp-p, 75ohm composite
Lens	4.0 mm / F 2.0
Focus Distance (mm)	Infinity
LED	None
Storage Temperature	-30 to 60 Degree C
Working Temperature	-10 to 45 Degree C
Power Source	DC 5~12V
Power Current	100 mA (Max.)
Dimension (mm)	Ø 15.2 x 68.5

Camera Parameter Adjustable (UTC Controller)
(UTC-200 Sold separately)

Five buttons function for exposure, WB, Day & Night, image & setup, function setup, reset. (enter, up, down, left, right) Toggles

