
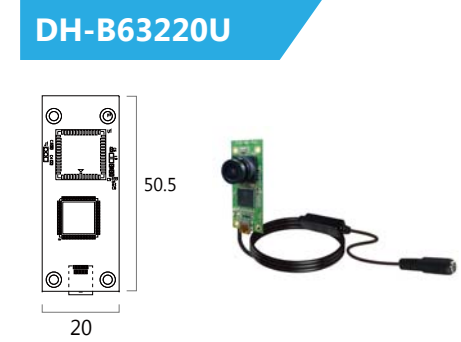


Unit: ± 0.5 mm

Feature

- Full HD 1080p HDMI Camera
- High Sensitivity!
- High Performance
- Full HD Image Pixel

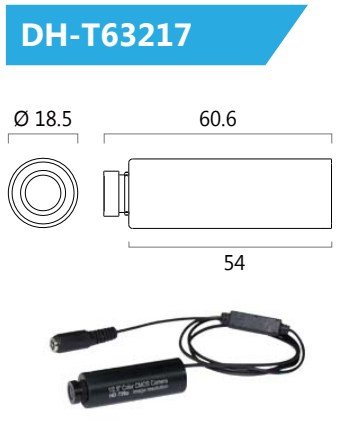

Specification

Model		T63217	B63217	B63220U
Dimensions (mm)		18.5 × 60.8	17.4 × 40	20 × 50.5
Frame Rate (Max.) (Specify when ordering)	HD	1280 × 720 @30 fps		
	FD	1920 × 1080 @30 fps		
Pixel Size (um)		4.2 × 4.2		
Image Sensor		1/2.9" Digital 1080p Color CMOS Camera		
Image Area (mm)		5.51 × 3.1		
Scan Mode		Progressive		
Sensitivity		7.0 V / Lux.sec		
Dynamic Range		55.1 dB		
SNR Range		39.8 dB		
Storage Temperature		-40 To 150 Degree C		
Working Temperature		-10 To 105 Degree C		
Interface		HDMI D Type		
Power Source		DC 5~12 V		
Power Current (Min.) (Specify when ordering)	HD	5 V / 350 mA, 12 V / 150 mA		
	FD	5 V / 430 mA, 12 V / 180 mA		

DH-T63217HD-2328

SERIES	CONNECTOR	CAMERA BODY	DISPLAY	RESOLUTION
DH HDMI	N/A Micro HDMI Type D	B Board Type T Tube Type V Tube Type + Dimmer	Front View 63217 Color Up View 63220U Color	HD 1280 × 720 FD 1920 × 1080
LENS				
Code	Specification	Thread	Resolution	View Angle
2328	2.33 mm / F 2.8	M 12 x P 0.5	14 MP	TBD°
3020	3.0 mm / F 2.0	M 10 x P 0.5	5 MP	125° / 100°
6022	6.0 mm / F 2.2	M 12 x P 0.5	1 MP	56°
1220	12.0 mm / F 2.0	M 12 x P 0.5	5 MP	28°

MISUMI offers different lenses to match with HDMI camera