



Unit: ± 0.5 mm


B62012
Board Type

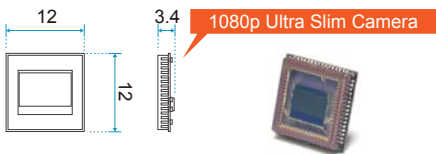


S62012
Forming Type

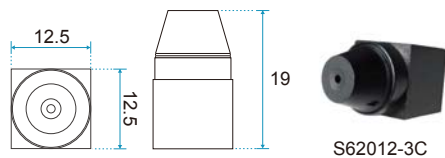


S62012-3C

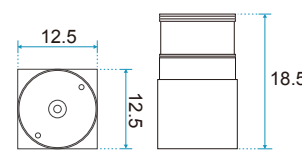


S62012-3F

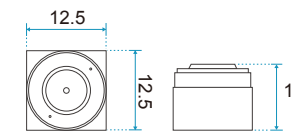


S62012-3T

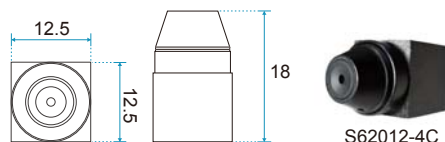

S62012-4C

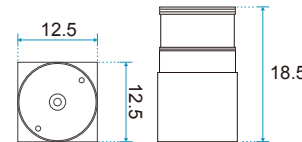


S62012-4F

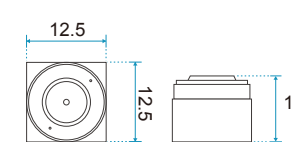

S62012-4T

 - Ultra Slim Camera Module
- 1080p High Resolution
- AHD / CVI / TVI / PVI (Specify When Ordering)



BNC Female
Video Output

DC Plug Female
Power Input
(DC 5~12V)

AHD-S62012A-3C

SERIES	CAMERA BODY	DISPLAY	MICROPHONE
AHD AHD CVI CVI TVI TVI PVI PVI	Front View S Forming Type B Board Type	62012 Color	A External N/A None
LED	CABLE	LENS	
L White LED LH High-Intensity White LED L8 IR 850 nm LED L9 IR 940 nm LED	C Cable + Wires Out N/A Cable + Connector	3C 3.8 mm / F 2.0 (86°) 3F 3.7 mm / F 2.0 (87°) 3T 3.1 mm / F 3.4 (91°) 4C 4.3 mm / F 2.0 (71°) 4F 4.3 mm / F 2.0 (71°) 4G 4.0 mm / F 2.0 (75°) 4T 3.9 mm / F 3.9 (76°) 6F 6.38 mm / F 4.4 (51°)	

Specification

Model	B62012	S62012
Dimensions (mm)	12 x 12	12.5 x 12.5
Video Format	AHD / CVI / TVI / PVI	
Image Sensor	1/2.9" CMOS Color Camera Module	
Resolution	1920 x 1080	
Pixel Size (µm)	2.8 x 2.8	
Image Area (mm)	5.3984 x 3.0464	
Scan Mode	Progressive	
Sensitivity	25.7 k e-/Lux-sec.	
Dynamic Range	64.6 dB	
S/N Ratio	49.6 dB	
Shutter	Rolling	
Lens	Specify When Ordering	
View Angle	Specify When Ordering	
Focus Distance (mm)	Infinity	
LED	Specify When Ordering	
Storage Temperature	-30 to 60 Degree C	
Working Temperature	-10 to 45 Degree C	
Power Supply	DC 5~12V	
Power Current	80 mA (DC 12V) / 150 mA (DC 5V)	
Connector	Mini 4 Pin (Male)	
Cable Length (cm)	50 cm (OD 1.9 mm)	