 


Feature

- 1280 x 720 resolution.
- Easy to conceal, easy to operate,
and easily fits into any environment.
- Outstanding quality.

AHD-55D-12120 ▶



Specification

Model	55D
Video Format	AHD / CVI / TVI / PVI
Image Sensor	1/4" CMOS Color Peephole Door Camera
Resolution	1280 x 720
Pixel Size (μm)	3.0 x 3.0
Image Area (mm)	3.888 × 2.208
Scan Mode	Progressive
Sensitivity	11.4 V / (Lux.sec)
Dynamic Range	65 dB
S/N Ratio	44 dB
Shutter	Rolling
Lens	12120 1.21 mm / F 2.0 (143°)
(Specify When Ordering)	4H 4.5 mm / F 2.8 (H= 46° 44'; V= 27° 34'; D= 52° 49')
Focus Distance (mm)	Infinity
Storage Temperature	-30 to 60 Degree C
Working Temperature	-10 to 45 Degree C
Power Supply	DC 5~12V
Power Current	75 mA (DC 12V) / 140 mA (DC 5V)


55D-12120

1.21 mm / F 2.0 (143°)



55D-4H

4.5 mm / F 2.8 (52°)

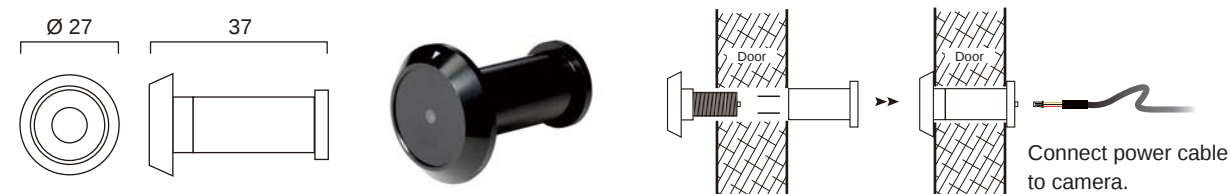

AHD-55D-12120

SERIES	CAMERA BODY	MICROPHONE	LENS
AHD AHD	55D Color	A External	12120 1.21 mm / F 2.0 (143°)
CVI CVI		N/A None	4H 4.5 mm / F 2.8 (52°)
TVI TVI			
PVI PVI			
	* D Peephole Door		