 
 
 
 
 
 
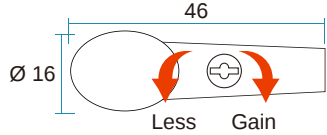
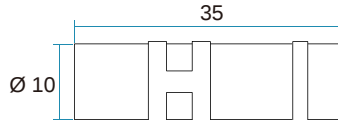
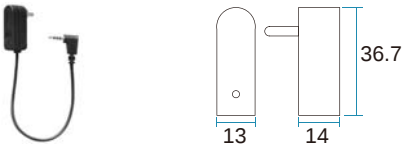
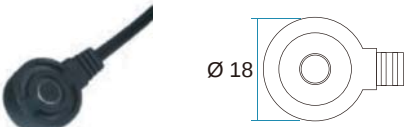
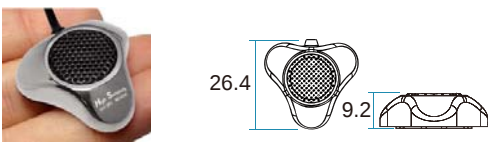
 
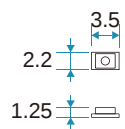
 


 
 
 
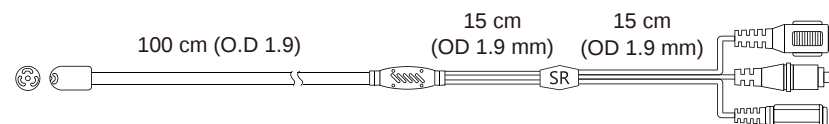
 
 
Unit: $\pm 0.2\text{mm}$

Image	Model	Sensitivity	Frequency	S/N Ratio (at 1,000Hz)	Impedance ($\pm 20\%$)	Power Input	Power Current	Note
 	MS-2300	-53 dB	20-10000 Hz	63 dB	150 ohms	DC 5~12 V	30 mA	
 	MS-3000	-44dB	20-16000 Hz	58 dB	600 ohms	DC 5~12 V	30 mA	
 	MS-3000S	-44 dB	20-16000Hz	58 dB	600 ohms	DC 5~12 V	30 mA	
 	MS-3100	-44 dB	20-16000 Hz	58 dB	150 ohms	DC 12 V	30 mA	
 	MS-3200	-44 dB	20-16000 Hz	58 dB	150 ohms	DC 5~12 V	30 mA	
 	MS-3300	-65 dB	20-10000 Hz	63 dB	150 ohms	DC 5~12 V	30 mA	
 	MS-3500	-44 dB	20-16000 Hz	58 dB	150 ohms	DC 12 V	20 mA	Gain control value changeable
 	MS-3600	-44 dB	20-16000 Hz	58 dB	150 ohms	DC 12 V	30 mA	

Unit: $\pm 0.2\text{mm}$

Image	Model	Sensitivity	Frequency	S/N Ratio (at 1,000Hz)	Impedance ($\pm 20\%$)	Power Input	Power Current	Note
	MS-3900	-44 dB	20-16000 Hz	58 dB	150 ohms	DC 12 V	30 mA	
	MS-6000	-44dB	20-16000 Hz	58 dB	600 ohms	DC 5~12 V	30 mA	
	MS-6200	-44 dB	20-16000Hz	58 dB	600 ohms	DC 12 V	30 mA	
	MS-6300	-44 dB	20-16000 Hz	58 dB	150 ohms	DC 5~12 V	30 mA	
	MS-B5300D	-25 dB~ -19 dB V/Pa	3.25 MHz	62 dB	—	DC 5 V	30 mA	Digital Microphone
 Coming Soon	MS-B5300DS	-25 dB~ -19 dB V/Pa	3.25 MHz	62 dB	-	DC 5 V	60 mA	Digital Microphone
	MS-T5300D	-25 dB~-19 dB V/Pa	3.25 MHz	62 dB	—	DC 5 V	30 mA	Digital Microphone
	MS-8300	-53.5 dB	100~10000 Hz	64 dB	4.4 K	DC 5~12 V	30 mA	

Unit: ± 0.2mm

MS-2300S
 RCA Female / DC Female

MS-2300SM
 RCA Male / DC Female

MS-2300SF
 RCA Male / DC Female (Combine)

MS-2300SE
 RCA Female / DC Female / DC Male

MS-2300SW
 Wires Output

MS-2300SP
 Phone Plug / DC Female


MS-2300SM



SERIES	TYPE	CONNECTOR
MS Accessory	Size (mm)	Analog
	2300S Ø 4.4 x 7.2	N/A RCA (F) / DC (F)
	3000 Ø 8 x 18	M RCA (M) / DC (F)
	3000S Ø 6 x 10	F RCA (M) / DC (F) (Combine)
	3100 Ø 7 x 15.7	E RCA (F) / DC (F) / DC (M)
	3200 Ø 7.3 x 33	W Wires out
	3300 6 x 18	P Phone plug / DC (F)
	3500 Ø 16 x 46	PC Phone plug (Ø 3.5 mm)
	3600 Ø 10 x 35	
	3900 14 x 36.5	
	6000 Ø 18	
	6200 26.4 x 9.2	UVC (5300 / T5300)
	6200ALC 26.4 x 9.2	D USB 2.0 Type A
	6300 3.5 x 22	
	5300 2.2 x 3.5	
	T5300 Ø 4 x 12	
	8300 Ø 2.6 x 3.1	
	* T Tube	
	*ALC Automatic Level Control	