


( NOTE : Just camera without LENS  
Lens unit diameter height for other lenses , please inquire for details.)

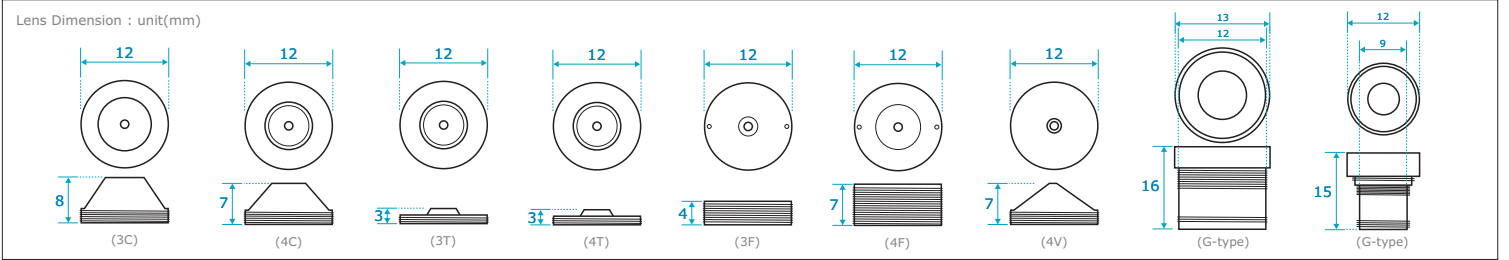

| Model                      | MO-S2612                                 | MO-S2615 | MO-S2617 | MO-S2618 | MO-N2631 |
|----------------------------|--|----------|----------|----------|----------|
| Video system               | NTSC / PAL                               |          |          |          |          |
| Number of effective pixels | 510 x 496 (NTSC) , 628 x 586 (PAL)       |          |          |          |          |
| Image sensor               | 1/3" CMOS Color Camera                   |          |          |          |          |
| Resolution(TV Lines)       | 380 TV Lines                             |          |          |          |          |
| S/N Ratio                  | more than 48dB                           |          |          |          |          |
| Minimum illumination       | 0.2 Lux / F1.2                           |          |          |          |          |
| Electronic shutter         | 1/50 - 1/125,000                         |          |          |          |          |
| Horizontal sync frequency  | NTSC(EIA)-15.73kHz , PAL (CCIR)-15.62    |          |          |          |          |
| Vertical sync frequency    | NTSC(EIA)-60Hz , PAL(CCIR)-50Hz          |          |          |          |          |
| Camera consumption         | 0.45                                     |          |          |          |          |
| Video output               | 1Vp-p , 75ohm composite                  |          |          |          |          |
| Audio output               | 20-1600Hz , SN more than 58dB (Optional) |          |          |          |          |
| Storage temperature        | -30 to 60 Degree C                       |          |          |          |          |
| Working temperature        | -10 to 45 Degree C                       |          |          |          |          |
| Power source               | DC 5-12V                                 |          |          |          |          |
| Power current              | 60 mA                                    |          |          |          |          |

**Order information**

| Dimension (mm) | Lens                             | Lens (Φ) | Electronic Shutter     |
|----------------|----------------------------------|----------|------------------------|
| MO-S2612G      | 3.6mm / F2.0                     | Φ12      | 1/50<br> <br>1/125,000 |
| MO-S2612P-xx   | Pin Hole Lens                    | Φ9       |                        |
| MO-S2615-G     | 3.6mm / F2.0                     | Φ12      |                        |
| MO-S2615P-xx   | Pin Hole Lens                    | Φ12      |                        |
| MO-S2617-G     | 3.6mm / F2.0                     | Φ12      |                        |
| MO-S2617P-xx   | Pin Hole Lens                    | Φ12      |                        |
| MO-S2618-G     | 3.6mm / F2.0                     | Φ12      |                        |
| MO-S2618P-xx   | Pin Hole Lens                    | Φ12      |                        |
| MO-N2631       | Pin Hole Lens (Hidden in button) | Φ9       |                        |

- MO-S26xxA-P(G) ▶ **A** : With Microphone
- MO-S26xx-P(G) ▶ **26** : 1/3" Color **CCIQ** Camera

Order in advance

**Pin hole Lens**

| 3C         | 4C         | 3F         | 4F         | 3T         | 4T         |
|------------|------------|------------|------------|------------|------------|
|            |            |            |            |            |            |
| 3.7mm/F2.0 | 4.3mm/F2.0 | 3.7mm/F2.0 | 4.3mm/F2.0 | 3.1mm/F3.4 | 3.9mm/F3.9 |

